


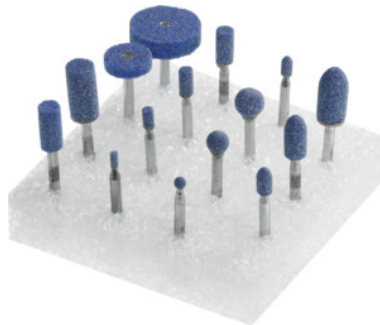

## Grinding points set fine, AW-CER, Number of grinding points: 15



### Order data

Order number	550305 15
GTIN	4007220947616
Item class	55E

### Description

#### Version:

Grinding point with **mixed grit (AW-CER)** in **hardness J**. Soft bonded combination of **white aluminium oxide** and **ceramic micro-crystalline sintered aluminium oxide** with high self-sharpening characteristics for consistently high metal removal rates coupled with cool grinding behaviour (Pferd designation AWCO).

Assortment of grinding points in the most popular shapes and sizes.

#### Application:

Recommended cutting speed 30 – 50 m/s.

For surface grinding of superalloys that are difficult to grind such as **titanium materials, nickel** and **cobalt-based alloys**, and also **hardened steel**.

#### Supplied with:

1 each grinding point ZY0205 / ZY0306 / ZY0408 / ZY0510 / ZY0613 / ZY0816 / ZY1303 / ZY2006 / KU03 / KU06 / KU08 / SP0306 / SP0408 / SP0613 / SP0816.

Grinding medium code: Ceramic

Shaft length: 30 mm

### Technical description

Number of grinding points	15
Grit designation	fine

Grinding media	Ceramic grit (CER)
Grinding medium code	Ceramic
Product name attribute	AW-CER
Shank Ø	3 mm
Shaft length	30 mm
Type of product	Grinding point