



Transport equipment

Product data sheet

Article no.: 1187 Dolly

Welded construction with aluminium platform with ribbed structure. 4 swivel castors, wheels with TPE tyres, hubs with precision deep groove ball bearing. 2 swivel castors with wheel locks, according to the European Standard EN 1757-3 (safety of platform trolleys).

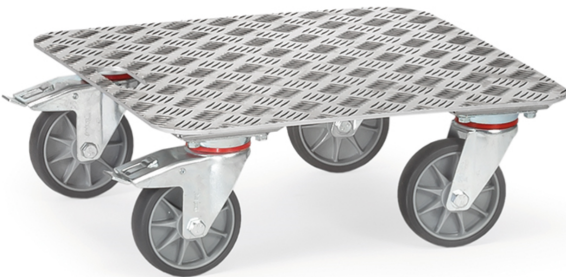

Technical Details:



Total load capacity (kg)	250
Length of usable platform (mm)	500
Width of usable platform (mm)	500
Height of loading platform (mm)	184
Total length (mm)	500
Total width (mm)	500
Total height (mm)	184
Tyres	TPE
Wheel size (mm)	125 x 32
Weight (kg)	9
Country of origin	Germany
Warranty (years)	10
Customs tariff number	76169990
GTIN	4017976011875