



Transport equipment

Product data sheet

Article no.: 6951 Moving gear adjustable

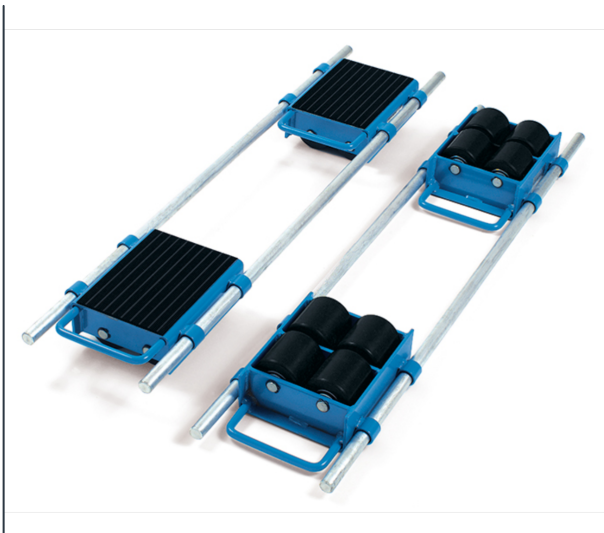

Moving gear for the easy and safe transport of machines and other heavy goods. Sturdy welded steel construction with handles made of round steel, powder coated blue RAL 5007. Carrying platforms with anti-slip rubber cover. Big nylon rolls with roller bearings. Scope of delivery: 2 transport rollers and 2 connecting rods made of round steel. Warranty: 2 years.

Technical Details:

Total load capacity (kg)	6000
Total length (mm)	320
Total width (mm)	268
Total height (mm)	110
Length of usable platform (mm)	250
Width of usable platform (mm)	200
Number of axes	4
Number of rolls	8
Wheel size (mm)	85 x 90
Tyres	Nylon
Note	adjustable range: 500 - 1190 mm
Weight (kg)	30
Country of origin	China
Warranty (years)	2
Customs tariff number	73269098
GTIN	4017976069517