

Product Datasheet model uvex i-5 guard 9183 180

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

1. Product Characteristics

- modern safety spectacle in technological design
- soft, flexible nose pad for maximum comfort and a non-slip fit
- x-tended eyeshield provides additional protection from flying particles, dust and dirt
- x-tended sideshield for increased side protection
- multi-level side arm inclination adapts easily to any facial shape
- soft, extendable x-twist side arm technology offers adaptable, pressure-free comfort and a stable non-slip fit
- soft side arm ends ensure a pressure-free and non-slip fit
- including extra frame for increased wearing comfort and close fit
- with proven uvex supravision lens coating technology
- metal-free

2. Technical Details Body

Frame	
Material	TPU / TPE / POM
Features	multi-level inclination, individual adjustable
Colour	blue, anthracite
Extra frame (guard)	
Material	TPEE / TPR
Colour	anthracite
Art. No. replacement frame	91836001
Marking	
Manufacturer 's ID code	W
Applicable EN norm	166
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Conformity symbol	CE

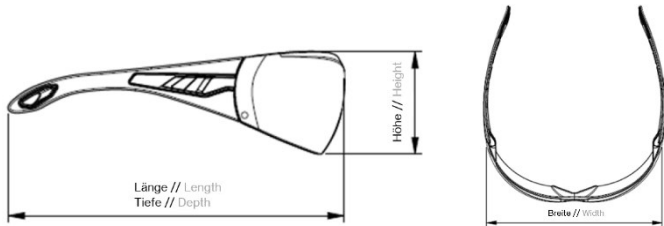
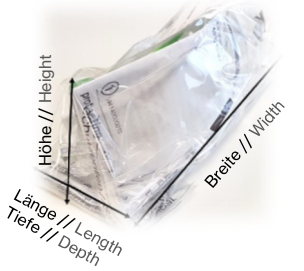
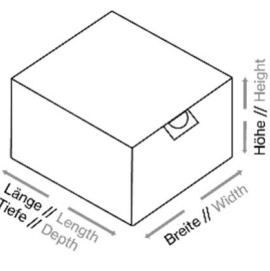
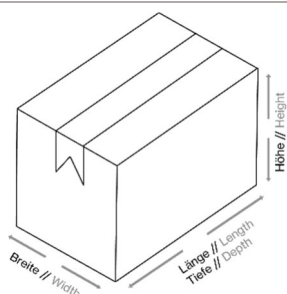
3. Technical Details Lens

Material	PC
Thickness	1,91 mm at PD
Coating	uvex supervision excellence
Colour	clear
UV protection	UV400
Marking	
Filter	2C-1,2 (EN 170)
Manufacturer 's ID code	W
Optical class	1
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Scratch resistance	K
Antifog	N

Conformity symbol	CE
Factory symbol	

4. Logistical Information

Product

Weight	35g		
Dimensions (L x W x B) in approx. mm	 <p style="text-align: right;">picture only for reference</p>		
	158 x 148 x 50		
	Packing unit 1	Packing unit 2	Packing unit 3
EAN Code	4031101827957	4031101827957	4031101827957
Quantity in pcs.	1	5	160
Dimensions (L x W x H) in approx. mm	 <p style="text-align: center;">picture only for reference</p>		
	60 x 150 x 58	190 x 165 x 78	600 x 400 x 400
Net weight	35g	175g	5.6 kg
Gross weight	61g	362g	12.48 kg
Country of Origin	Germany		

5. Miscellaneous

Standards	EN 166 + EN 170
PPE Category	Category II