

workwear

uvex suXXeed ESD Ladies coat



uvex suXXeed ESD Ladies coat

model-no.: 7463

colour: white or graphite

material: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

elastic cuffs: 98 % PES, 2 % Resistat

size: XS – 4XL

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



Product description:

- ergonomic fit with „high rise“ sleeve construction and side panel
- lapel collar
- elastic cuffs
- front centre closure with concealed press studs
- 2 side pockets
- breast darts
- darts in front and back
- breast pocket inside on the left
- embroidery on the left upper arm
- ESD label on the hem bottom left
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100


workwear

uvex suXXeed ESD Ladies coat

colour ways



model-no.: 7463
article-no.: 88259

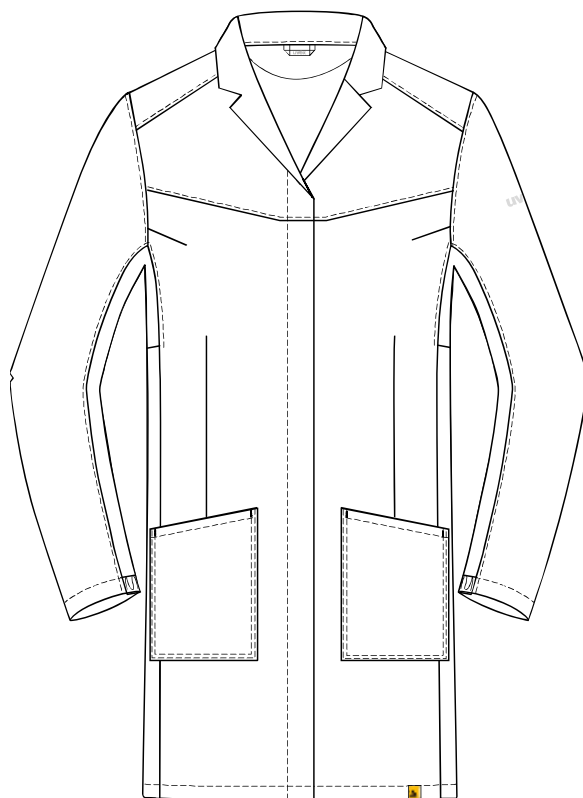

model-no.: 7463
article-no.: 88258

workwear

uvex suXXeed ESD men coat



uvex suXXeed ESD men coat

model-no.: 7464

colour: white or graphite

materiel: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

elastic cuffs: 98 % PES, 2 % Resistat

size: XS – 6XL

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



Product description:

- ergonomic fit with „high rise“ sleeve construction and side panel
- lapel collar
- elastic cuffs
- front centre closure with concealed press studs
- 2 side pockets
- breast darts
- darts in front and back
- breast pocket inside on the left
- embroidery on the left upper arm
- ESD label on the hem bottom left
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100


workwear

uvex suXXeed ESD men coat

colour ways



model-no.: 7464
article-no.: 88261

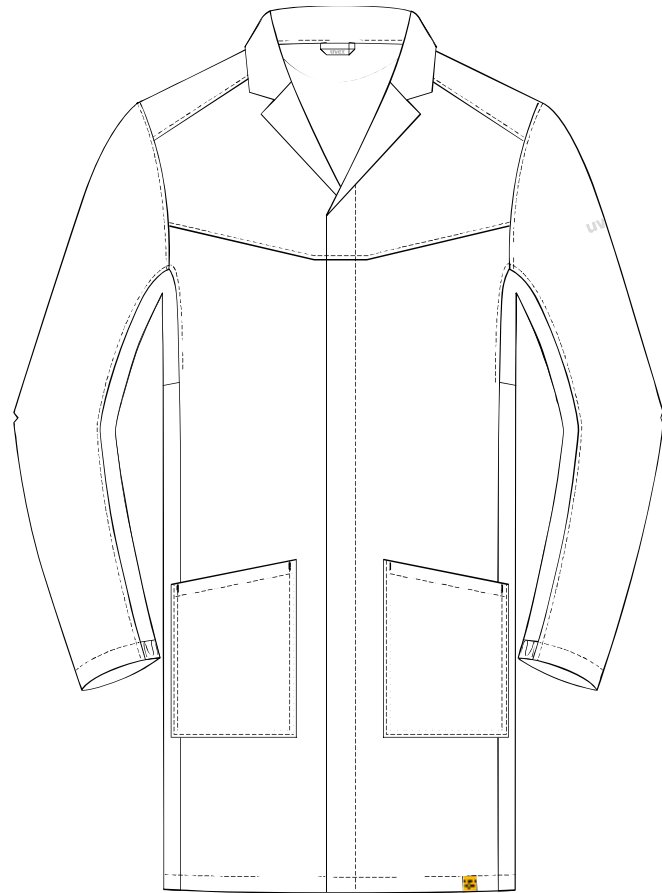

model-no.: 7464
article-no.: 88260

workwear

uvex suXXeed ESD Ladies jacket



uvex suXXeed ESD Ladies jacket

model-no.: 7659

article-no.: 88488

colour: graphite

material: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

elastic cuffs: 98 % PES, 2 % Resistat

size: XS-4XL

sales unit: 1 piece

No PPE
EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



Product description:

- ergonomic fit with „high rise“ sleeve construction
- stand-up collar
- stretch insert in the sleeve hem
- front center with concealed zipper and attached panel
- 1 breast pocket on the left with attached panel
- 2 side pockets
- embroidery on the left upper arm
- ESD label on the hem bottom left
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100

OEKO-TEX®
CONFIDENCE IN TEXTILES
STANDARD 100
S20-0516 HOHENSTEIN HTTI
Tested for harmful substances.
www.oeko-tex.com/standard100

workwear

uvex suXXeed ESD men jacket



uvex suXXeed ESD men jacket

model-no.: 7465

article-no.: 88262

colour: graphite

material: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

elastic cuffs: 98 % PES, 2 % Resistat

size: S – 6XL

sales unit: 1 piece

No PPE
EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



INDUSTRIAL WASH ●●

Product description:

- ergonomic fit with „high rise“ sleeve construction
- stand-up collar
- stretch insert in the sleeve hem
- front center with concealed zipper and attached panel
- 1 breast pocket on the left with attached panel
- 2 side pockets
- embroidery on the left upper arm
- ESD label on the hem bottom left
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100

OEKO-TEX®
CONFIDENCE IN TEXTILES
STANDARD 100
S20-0516 HOHENSTEIN HTTI



Tested for harmful substances.
www.oeko-tex.com/standard100

workwear

uvex suXXeed ESD Ladies trousers



uvex suXXeed ESD Ladies trousers

model-no.: 7660

article-no.: 88489

colour: graphite

material: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

size: 36-54, 19-26

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



Product description:

- ergonomic fit with inserted leg wedge and knee shaping
- stretchy waistband with 5 belt loops
- Patentbutton and fly with zipper
- 2 side pockets
- 1 back pocket on the right
- 1 leg pocket on the left with a fold and a flap with concealed press studs
- embroidery on back pocket
- ESD label on the flap
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100



workwear

uvex suXXeed ESD men trousers



uvex suXXeed ESD men trousers

model-no.: 7466

article-no.: 88263

colour: graphite

material: 66,5 % PES, 32 % CO,
1,5 % antistatic fibres
245 g/m²

size: 23-32, 42-66, 90-110

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. 10⁶ Ω)



Product description:

- ergonomic fit with inserted leg wedge and knee shaping
- stretchy waistband with 5 belt loops
- Patentbutton and fly with zipper
- 2 side pockets
- 1 back pocket on the right
- 1 leg pocket on the left with a fold and a flap with concealed press studs
- embroidery on back pocket
- ESD label on the flap
- industrial cleaning tested according to DIN EN ISO 15797
- Oeko-Tex® Standard 100

workwear

uvex suXXeed ESD Seamless Shirt



uvex suXXeed ESD Seamless Shirt

model-no.: 7467

colour: black

material: 91 % polypropylene,
7 % polyamide,
2 % silver

size men:

XS/S, M/L, XL/2XL, 3XL/4XL

size women:

XS, S/M, L/XL, 2XL/3XL, 4XL

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. $10^5 \Omega$)



Product description:

- seamless Shirt for perfect wearing comfort
- different knitting techniques for better movement
- crew neck
- ½ raglan sleeves
- optimal moisture management, fast-drying, anti-bacterial and odour-neutralising
- ESD label on the hem bottom left
- Oeko-Tex® Standard 100



workwear

uvex suXXeed ESD Poloshirt



uvex suXXeed ESD Poloshirt

model-no.: 9872

article-no.: 98627

colour: white

material: 45 % CO, 44 % PES,
2 % antistatic fibres
185 g/m²

size: S bis 2XL

sales unit: 1 piece

No PPE

EN 61340-5-1



(point-to-point resistance approx. 10¹¹ Ω)



Product description:

- cross striped ESD Poloshirt
- front part with cross pass
- polo-collar with visible 2-button placket