

Product Datasheet model uvex astrospec 2.0 CB 9164 276

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

1. Product Characteristics


- classic safety spectacle with flat lens for a wide field of vision
- ergonomically shaped side arms with multi-incline points allow for a high level of individualization to ensure a good fit for all facial shapes and head widths
- side arms with soft-grip temple ends provide a comfortable, secure fit without pressure
- nose bridge designed for all-day comfort
- robust polycarbonate lens with uvex's proven supravision coating technology – permanent anti-fog and scratch-resistant lens
- UV400 – 100 % protection against dangerous UVA and UVB radiation up to 400 nm
- lower nose bridge, high cheekbone design (ISO 18526-4:2020)

2. Technical Details Body**Front piece**

Material	PC+TPU
Colour	blue

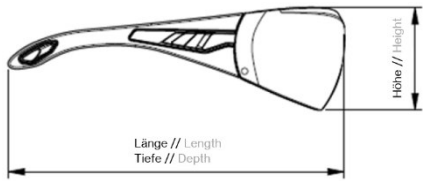

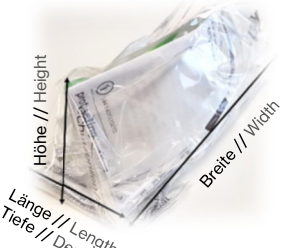
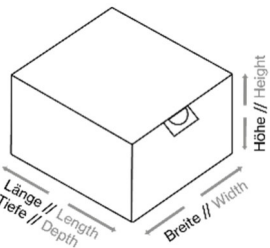
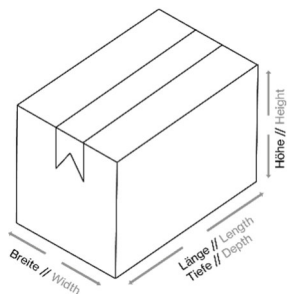
Ratchet	
Material	POM
Colour	grey
Rivet	
Material	brass, nickel-plated
Side arms	
Material	PC+TPU/TPE
Features	individually adjustable due to multi-incline points
Colour	blue, light blue
Marking	
Manufacturer 's ID code	W
Applicable EN norm	166
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Conformity symbol	CE

3. Technical Details Lens	
Material	PC
Thickness	2.2 mm at PD
Coating	uvex supravision extreme
Colour	
UV protection	UV400
Marking	
Filter	2C-1.2 (EN 170)
Manufacturer 's ID code	W
Optical class	1
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T

Scratch resistance	K
Antifog	N
Conformity symbol	CE
Factory symbol	

4. Logistical Information

Product

Weight	43g		
Dimensions (L x W x B) in approx. mm	  <p style="text-align: right;">picture only for reference</p>		
	145 x 153 x 58		
	Packing unit 1	Packing unit 2	Packing unit 3
EAN Code	4031101925578	4031101925578	4031101925578
Quantity in pcs.	1	10	160
Dimensions (L x W x H) in approx. mm	 <p style="text-align: center;">picture only for reference</p>		
	55 x 160 x 65	185 x 290 x 97	600 x 400 x 400
Net weight in approx. g	43	430	6,880
Gross weight in approx. g	73	835	14,230
Country of Origin	Germany		

5. Miscellaneous

Standards	EN 166 + EN 170
PPE Category	Category II