

Product Datasheet model uvex x-fit guard 9199 180

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

1. Product Characteristics

- classic safety spectacles with good coverage of the whole eye area
- lightweight
- innovative hinged side arm design with option of attaching the uvex Comfort Slider for an optimum fit
- including extra frame for increased wearing comfort and close fit
- uvex supervision coating technology
- metal-free


2. Technical Details Body**Temple**

Material	ABS
Colour	grey translucent

Extra frame

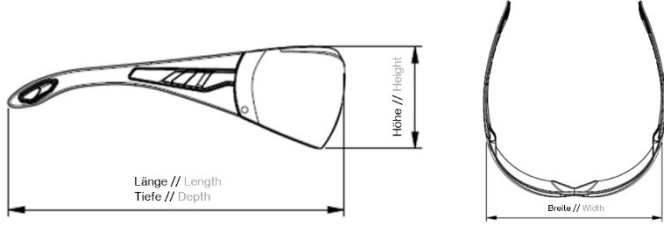
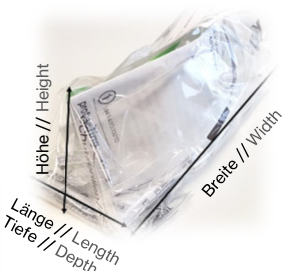
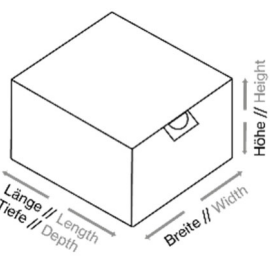
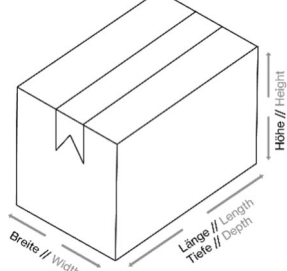
Material	PC/PBT / EVA
Colour	black
Art. No. replacement frame	9199001

Marking	
Manufacturer 's ID code	W
Applicable EN norm	166
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Conformity symbol	CE

3. Technical Details Lens	
Material	PC
Thickness	1,9 mm at PD
Coating	uvex supravision excellence
Colour	clear
UV protection	UV400
Marking	
Filter	2C-1,2 (EN 170)
Manufacturer 's ID code	W
Optical class	1
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Scratch resistance	K
Antifog	N
Conformity symbol	CE
Factory symbol	

4. Logistical Information

Product

Weight	29g		
Dimensions (L x W x B) in approx. mm	 <p style="text-align: right;">picture only for reference</p>		
	155 x 142 x 46		
	Packing unit 1	Packing unit 2	Packing unit 3
EAN Code	4031101821665	4031101821665	4031101821665
Quantity in pcs.	1	5	160
Dimensions (L x W x H) in approx. mm	 <p style="text-align: center;">picture only for reference</p>		
	65 x 152 x 58	190 x 165 x 78	600 x 400 x 400
Net weight	29g	145g	4,64 kg
Gross weight	55g	332g	11,52 kg
Country of Origin	Germany		

5. Miscellaneous

Standards	EN 166 + EN 170
PPE Category	Category II