

**Product Datasheet model uvex x-fit pro guard 9199 680**

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,  
D-90766 Fürth**

**1. Product Characteristics**

- functional and sporty design
- soft nose pad with x-design for maximum wearer comfort
- elastic side arms ensure a pressure-free fit thanks to uvex duo component technology
- flexible modular system allows attachment of functional accessories
- including extra frame for increased wearing comfort and close fit
- uvex supravision coating technology
- metal-free


**2. Technical Details Body****Temple**

Material	ABS
Colour	blue, anthracite

**Extra frame**

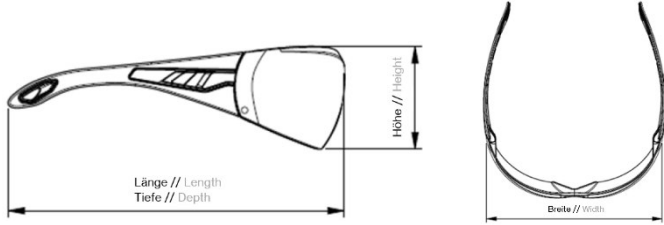
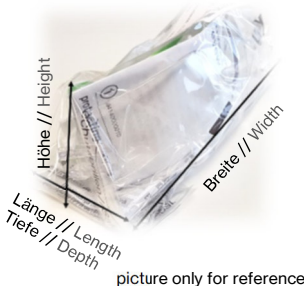
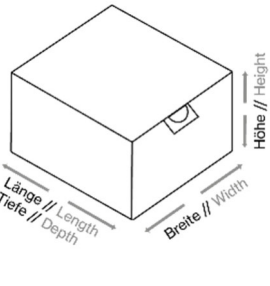
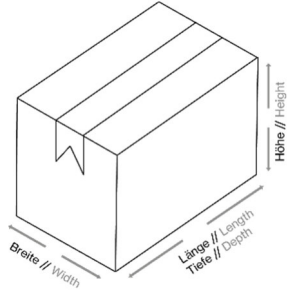
Material	PC/PBT / EVA
Colour	black
Art. No. replacement frame	9199001

<b>Marking</b>	
Model No.	9199
Manufacturer 's ID code	W
Applicable EN norm	166
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Conformity symbol	CE

<b>3. Technical Details Lens</b>	
Material	PC (Lens) TPE (x-nose)
Thickness	1,9 mm at PD
Coating	uvex supravision excellence
Colour	clear (Lens) anthracite (x-nose)
UV protection	UV400
<b>Marking</b>	
Filter	2C-1,2 (EN 170)
Manufacturer 's ID code	W
Optical class	1
Impact resistance	F (45 m/s)
Resistance to high speed particles at extremes of temperature	T
Scratch resistance	K
Antifog	N
Conformity symbol	CE
Factory symbol	

## 4. Logistical Information

### Product

Weight	30g		
Dimensions (L x W x B) in approx. mm	 <p style="text-align: right;">picture only for reference</p>		
	<b>Packing unit 1</b>	<b>Packing unit 2</b>	<b>Packing unit 3</b>
EAN Code	4031101821702	4031101821702	4031101821702
Quantity in pcs.	1	5	160
Dimensions (L x W x H) in approx. mm	 <p style="text-align: center;">picture only for reference</p>		
	65 x 158 x 58	190 x 165 x 78	600 x 400 x 400
Net weight	30g	150g	4,8 kg
Gross weight	56g	337g	11,68 kg
Country of Origin	Germany		

## 5. Miscellaneous

Standards	EN 166 + EN 170
PPE Category	Category II