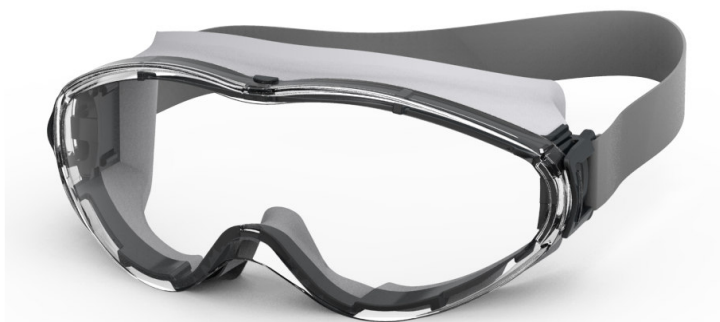



Product Datasheet model ultrasonic 9302 281**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

Product characteristics	<ul style="list-style-type: none">• goggles in sporty design, can also be worn over prescription spectacles• lenses can be changed• high mechanical strength (B: 120 m/s)• wide panoramic field of vision• hard and soft components create soft, pressure free seal for comfortable all day
Technical details	
Frame	Front piece
Material	PP/TPE
Feature	adjustable
Colour	black/grey
Headband	
Material	Neoprene
Features	individually adjustable
Colour	grey

Manufacturer's ID code	Marking W
Applicable EN norm	166
Field of use	3 (drops and splashes of liquid) 4 (large dust particles)
Impact resistance	B (120 m/s)
Conformity symbol	CE
Lens	
Material	PC
Thickness	2,2 mm
Coating	uvex supravision excellence
Colour	clear
UV protection	UV 400
Filter	Marking 2-1,2 (DIN EN 170)
Manufacturer's ID code	W
Optical class	1
Low-energy impact	B (120 m/s)
Surface resistance to fine particles	K
Antifog	N
Conformity symbol	CE
Factory symbol	

Miscellaneous

Weight

89 g

Packing

4 goggles per box

72 pieces in one carton

Standards

DIN EN 166 + DIN EN 170

PPE Category

Category II

Please note**For autoclaving please use uvex ultrasonic CR
9302.500**