

## Product information

# 13 62 180

### KNIPEX StriX®

Insulation strippers with cable shears





- Wire stripper with cable shears – two essential electrical installations tools in one pair of pliers
- Integrated cable shears for the clean cutting of Cu- and Al-cables without crushing
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 57 HRC
- Universal adjustment of the stripping blades by means of a knurled screw
- Slim dimensions for easy access
- Stripping of single-, multi- and fine stranded conductors with plastic or rubber insulation up to Ø 5 mm or 10 mm<sup>2</sup> cross-section
- Graduated jaw provides a visual orientation aid when stripping wire in standard lengths (11 mm and 16 mm)
- High-grade special tool steel, forged, multi stage oil-hardened



General	
Article No.	13 62 180
EAN	4003773081302
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
Weight	200 g
Dimensions	180 x 51 x 20 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable
Technical details	
Cutting capacity copper cable, multiple-stranded	50 mm <sup>2</sup>
Cutting capacity copper cable, multiple-stranded	Ø 15 mm
Stripping capacities in square millimetres	10.0 mm <sup>2</sup>
Stripping capacities (diameter)	Ø 5.0 mm
AWG	8


technical change and errors excepted

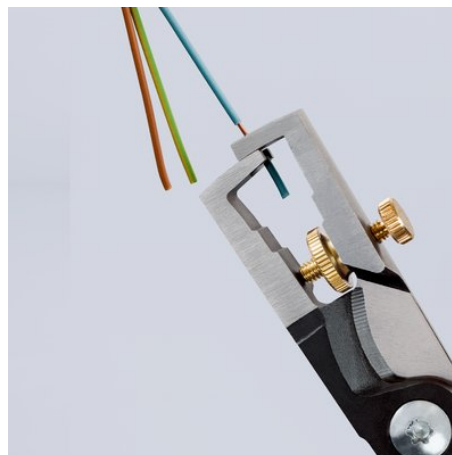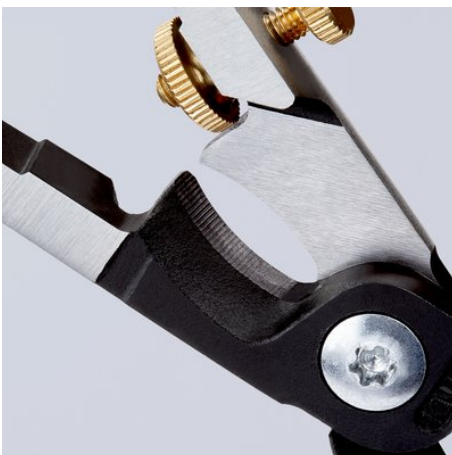

Induction-hardened precision cutter



Length mark: Profiling on the inner side helps when stripping wire in standard lengths (11 mm and 16 mm)

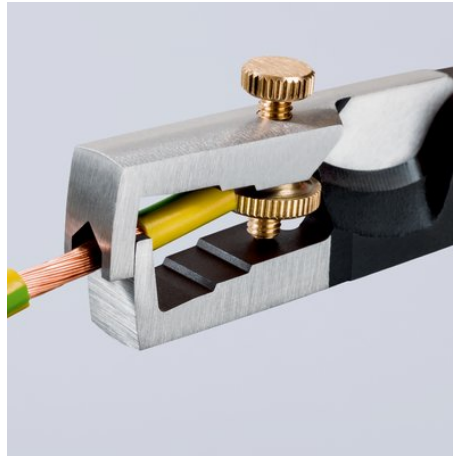

Induction-hardened shear blade with precisely ground cutting edges for crush-free cutting of copper and aluminium Lock nut prevents any unintentional adjustment cables of up to Ø 15 mm (5 x 2.5 mm<sup>2</sup>)