

Product information

22 02 140

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened

Round Nose Pliers

DIN ISO 5745




General

Article No.	22 02 140
EAN	4003773043430
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
Weight	129 g
Dimensions	140 x 57 x 18 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	28.0 mm
Head width (W3)	16.5 mm

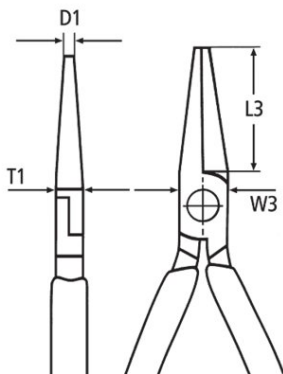

technical change and errors excepted

