

Product information

23 01 140

Flat Nose Pliers with cutting edges (Precision Mechanics Pliers)

DIN ISO 5745


- Suitable for finer gripping and cutting work
- Flat, long jaws, tapering
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 60 HRC
- High-grade special tool steel, forged, multi stage oil-hardened



General	
Article No.	23 01 140
EAN	4003773041290
Head	polished
Handles	plastic coated
Weight	75 g
Dimensions	140 x 52 x 12 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details	
Cutting capacities soft wire (diameter)	Ø 2.5 mm
Cutting capacities medium hard wire (diameter)	Ø 1.6 mm
Jaw thickness (joint) (T1)	7.0 mm
Tips width (W4)	3.0 mm
Tips thickness (D1)	4.5 mm
Jaw length (L3)	35.0 mm
Head width (W3)	12.5 mm

Technical details

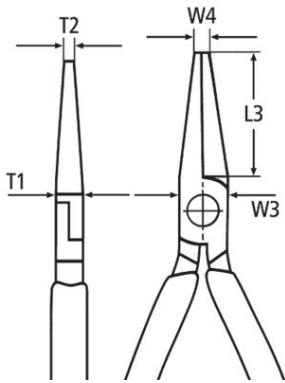

technical change and errors excepted