

Product information

30 11 160

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Chrome vanadium electric steel, forged, oil-hardened

Long Nose Pliers

DIN ISO 5745




General

Article No.	30 11 160
EAN	4003773023128
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	121 g
Dimensions	160 x 51 x 12 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	5.0 mm
Jaw length (L3)	46.5 mm
Head width (W3)	16.5 mm

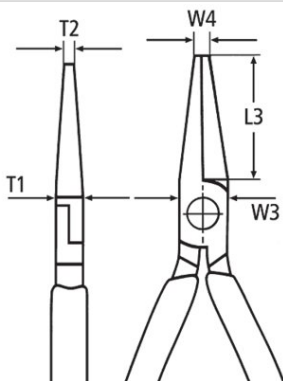

technical change and errors excepted