

## Product information

# 30 21 140


## Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, half-round jaws
- Chrome vanadium electric steel, forged, oil-hardened



| General                    |                       |
|----------------------------|-----------------------|
| Article No.                | 30 21 140             |
| EAN                        | 4003773042433         |
| Pliers                     | black atramentized    |
| Head                       | polished              |
| Handles                    | plastic coated        |
| Weight                     | 95 g                  |
| Dimensions                 | 140 x 54 x 13 mm      |
| Standard                   | DIN ISO 5745          |
| REACH compliant            | does not contain SVHC |
| RoHS compliant             | not applicable        |
| Technical details          |                       |
| Jaw thickness (joint) (T1) | 8.0 mm                |
| Tips width (W4)            | 2.5 mm                |
| Tips thickness (T2)        | 2.0 mm                |
| Jaw length (L3)            | 42.0 mm               |
| Head width (W3)            | 15.0 mm               |

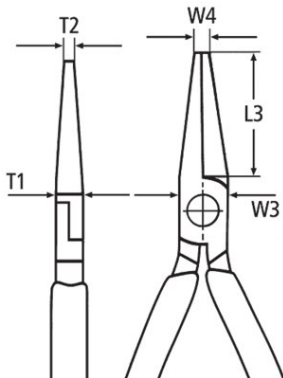

*technical change and errors excepted*