

Product information

37 41 125

Flat Nose Pliers

For precision mechanics

DIN ISO 9655

- Precision pliers for fine assembly work, e.g. in electronics and fine mechanics
- For gripping, holding, bending and adjusting
- Tips precision-ground
- Smooth gripping surfaces
- Edges carefully deburred
- Lap joint
- Round, pointed jaws to bend wire loops
- High-grade special tool steel, forged, oil-hardened




General

Article No.	37 41 125
EAN	4003773035152
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	76 g
Dimensions	125 x 50 x 12 mm
Standard	DIN ISO 9655
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Jaw thickness (joint) (D)	8.0 mm
Tips width (E)	2.0 mm
Tips thickness (F)	1.0 mm
Jaw length (B)	27.0 mm
Head width (A)	14.5 mm

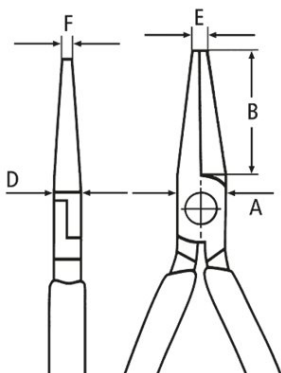

technical change and errors excepted