

Product information

38 11 200

- High bending strength of the pliers tips
- Straight, half-round jaws
- Vanadium electric steel; forged, oil-hardened

Mechanics' Pliers

DIN ISO 5745




General

Article No.	38 11 200
EAN	4003773035169
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	179 g
Dimensions	200 x 53 x 13 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm

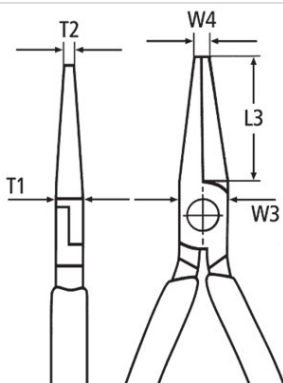

technical change and errors excepted