

## Product information

# 38 21 200

- High bending strength of the pliers tips
- 40° bent, half-round jaws
- Vanadium electric steel; forged, oil-hardened


## Mechanics' Pliers

DIN ISO 5745



General	
Article No.	38 21 200
EAN	4003773035176
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	175 g
Dimensions	200 x 47 x 13 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details	
Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm
Head angle	40 °

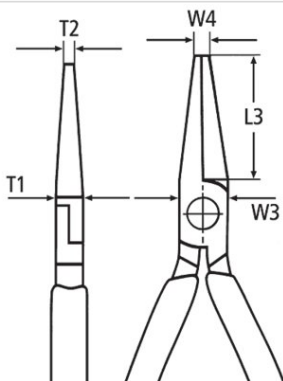

technical change and errors excepted