

## Product information

# 38 35 200 T

## Mechanics' Pliers

DIN ISO 5745

- Pliers with tether attachment point for mounting a fall protection system
- High bending strength of the pliers tips
- Vanadium electric steel; forged, oil-hardened




### General

Article No.	38 35 200 T
EAN	4003773083771
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Weight	210 g
Dimensions	200 x 54 x 20 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

### Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm
Drop Protection System	yes

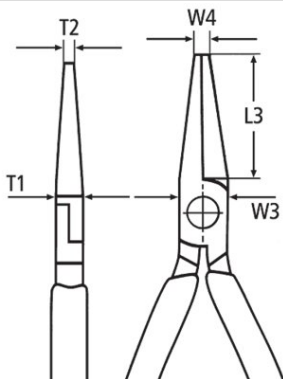

technical change and errors excepted