

## Product information

**69 01 130**

### End Cutting Nipper

For mechanics

DIN ISO 5748

- With cutting edges for soft, hard and piano wire; also suitable for thin copper wires
- Lap joint
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 62 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened




#### General

Article No.	69 01 130
EAN	4003773017974
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	111 g
Dimensions	130 x 50 x 13 mm
Standard	DIN ISO 5748
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

#### Technical details

Cutting capacities medium hard wire (diameter)	Ø 1.3 mm
Cutting capacities hard wire (diameter)	Ø 1.0 mm
Cutting capacities piano wire (diameter)	Ø 0.8 mm
Cutting capacities soft wire (diameter)	Ø 0.4 – 2 mm
Jaw length (B)	7.5 mm
Jaw thickness (joint) (D)	10 mm
Head width (A)	16 mm
Cutting edge length mm (C)	20.0 mm

## Technical details

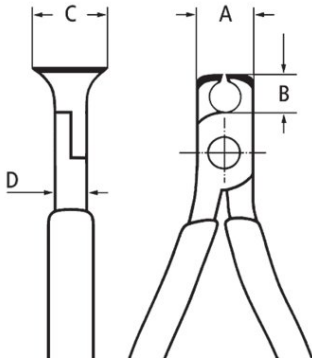

*technical change and errors excepted*