

Product information

95 62 190

Wire Rope Cutter

Forged

- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened




MM

General	
Article No.	95 62 190
EAN	4003773071976
Head	burnished
Handles	with multi-component grips
Weight	314 g
Dimensions	190 x 60 x 20 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable
Technical details	
Cutting capacities piano wire (diameter)	Ø 2.5 mm
Cutting capacity copper cable, multiple-stranded (diameter)	Ø 7.0 mm
Cutting capacities wire rope (diameter)	Ø 5.0 mm
Cutting capacities medium hard wire (diameter)	Ø 4.0 mm
AWG	8

technical change and errors excepted



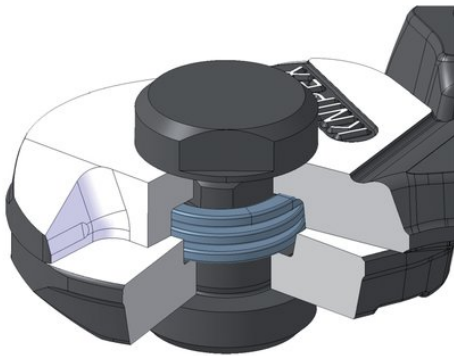

Internal opening spring