

Product information


97 22 240

Crimping Pliers



- With threaded holes for cutting copper and brass screws threaded M 2.6 / M 3 / M 3.5 / M 4 and M 5
- Bolted joint for higher stability and even movement
- Special steel, high-strength




General	
Article No.	97 22 240
EAN	4003773070726
Pliers	black lacquered
Handles	with multi-component grips
Weight	270 g
Dimensions	240 x 62 x 25 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details	
	
Application	insulated terminals + cable connectors
Capacity in square millimetres	0.5 — 6.0 mm ²
Number of crimping positions	3
AWG	20 — 10

technical change and errors excepted

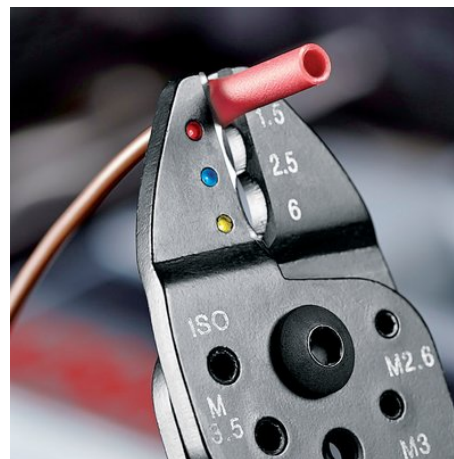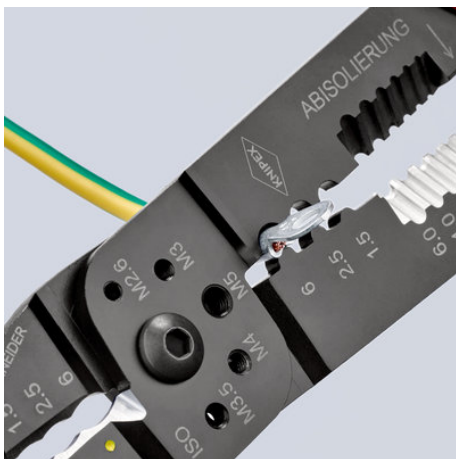

97 21 215

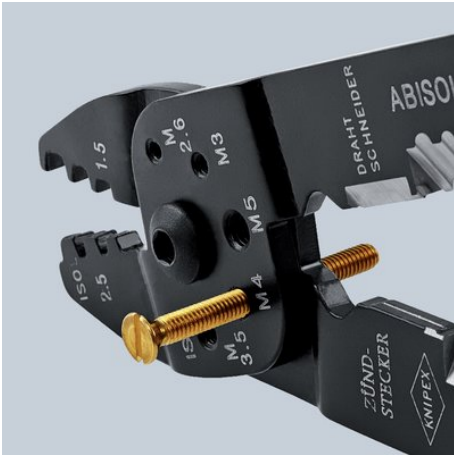

97 21 215 B



97 21 215 B



97 21 215 B



97 21 215 B