


## Product information

**97 49 04**

- Application: non-insulated open plug type connectors (plug width 2.8 + 4.8 mm) 0.1 - 2.5 mm<sup>2</sup>

### Crimping die

For non-insulated open plug-type connectors 2.8 + 4.8 mm

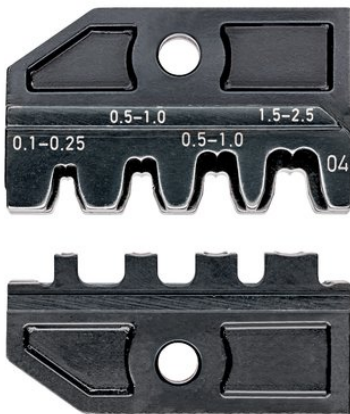

#### General

|                 |                |
|-----------------|----------------|
| Article No.     | 97 49 04       |
| EAN             | 4003773030850  |
| Weight          | 42 g           |
| Dimensions      | 50 x 10 mm     |
| REACH compliant | contains SVHC  |
| RoHS compliant  | not applicable |

#### Technical details



|                                |   |
|--------------------------------|---|
| Application                    | non-insulated open plug type connectors (plug width 2.8 + 4.8 mm) |
| Capacity in square millimetres | 0.1 — 2.5 mm <sup>2</sup>   |
| Number of crimping positions   | 4   |
| AWG                            | 26 — 14   |

*technical change and errors excepted*