


Product information

97 49 11

- Application: non-insulated crimp terminals, tube and compression cable lugs in accordance with DIN 46234 and DIN 46235 and non-insulated crimp, butt and press connectors in accordance with DIN 46341 and DIN 46267 4/6/10 mm²

Crimping die


For non-insulated crimp terminals, tube and compression cable lugs in accordance with DIN 46234 and DIN 46235 and non-insulated crimp, butt and press connectors in accordance with DIN 46341 and DIN 46267

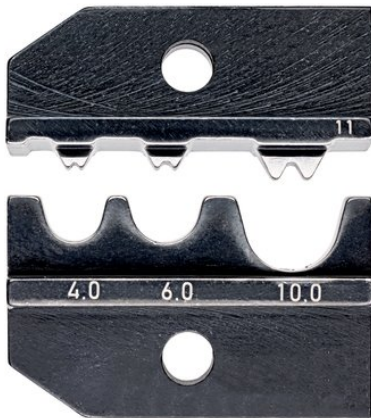

General

Article No.	97 49 11
EAN	4003773076902
Weight	37 g
Dimensions	12 x 32 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	non-insulated crimp terminals, tube and compression cable lugs in accordance with DIN 46234 and DIN 46235 and non-insulated crimp, butt and press connectors in accordance with DIN 46341 and DIN 46267
Capacity in square millimetres	4 / 6 / 10 mm ²
Number of crimping positions	3
AWG	12 / 10 / 8

technical change and errors excepted