


Product information

97 49 15

- Application: Flag terminals and non-insulated, open plug type connectors (6.3 mm connector width) 1.25-2.5 + 3.0-6.0 mm²

Crimping die

For plug connectors and non-insulated open plug-type connectors

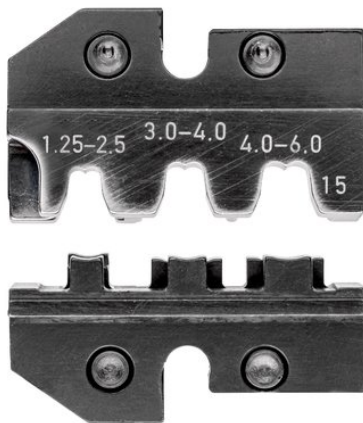

General

Article No.	97 49 15
EAN	4003773043164
Weight	56 g
Dimensions	50 x 17 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	for plug connectors and angled spade connectors according to DIN 46346 Form A (1.5 - 2.5 mm ²) 2 + 3 crimping die: for non-insulated, open lug connectors (straight version) according to DIN 46247 (2.5 – 6 mm ²)
Capacity in square millimetres	1.25 — 2.5 / 3 — 6 mm ²
Number of crimping positions	2
AWG	12 — 10

technical change and errors excepted