

Product information

97 99 391

Non-insulated wire ferrules

200 pieces each

DIN 46228-4: 2020-03

- Nominal size: 0.75 mm²
- Content: 200 pieces
- Non-insulated
- Material: E-Cu
- Surface electro tin plated
- Minimum coating thickness 3µm




General

Article No.	97 99 391
EAN	4003773076711
Standard	DIN 46228-4: 2020-03
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Cable	0.75 mm ²
AWG	18
L	6 mm
d1	1.2 mm
d2	2.3 mm
S	0.15 mm
Quantity	200
Material	Copper
Surface	Tinned

Technical details

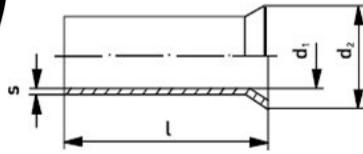

technical change and errors excepted