

Product information

98 01 07

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V Ⓞ

General

Article No.	98 01 07
EAN	4003773020134
Weight	55 g
Dimensions	13 x 23 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Width across flats S	7 mm
Length l max.	150 mm
Head thickness a max.	7 mm
Depth of crank h max.	18 mm
Head width b max. mm	12 mm

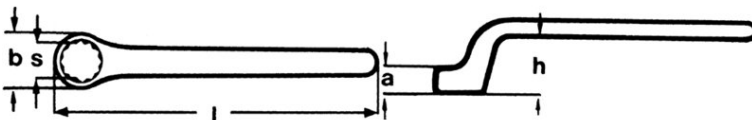

technical change and errors excepted

