

## Product information

# 98 01 08

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

## Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V ♻️

### General

Article No.	98 01 08
EAN	4003773020141
Weight	68 g
Dimensions	16 x 27 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

### Technical details

Width across flats S	8 mm
Length l max.	155 mm
Head thickness a max.	7 mm
Depth of crank h max.	19 mm
Head width b max. mm	14 mm

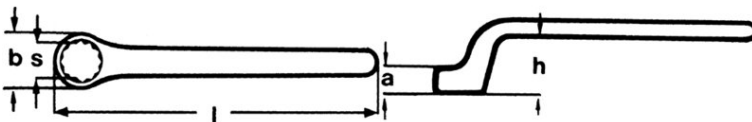

*technical change and errors excepted*

