

Product information

98 01 09

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V Ⓞ

General

Article No.	98 01 09
EAN	4003773020158
Weight	78 g
Dimensions	14 x 27 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Width across flats S	9 mm
Length l max.	165 mm
Head thickness a max.	8 mm
Depth of crank h max.	19 mm
Head width b max. mm	15.5 mm

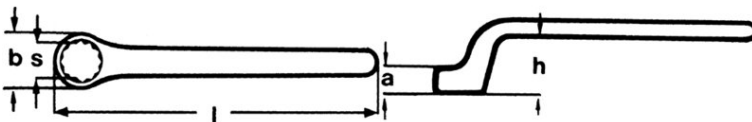

technical change and errors excepted

