

Product information

98 01 12

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V Ⓞ

General

Article No.	98 01 12
EAN	4003773020226
Weight	118 g
Dimensions	20 x 33 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Width across flats S	12 mm
Length l max.	185 mm
Head thickness a max.	10 mm
Depth of crank h max.	23 mm
Head width b max. mm	18.5 mm

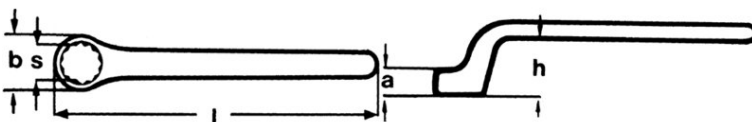

technical change and errors excepted

