

Product information

98 01 15

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V Ⓞ

General

Article No.	98 01 15
EAN	4003773020257
Weight	143 g
Dimensions	19 x 33 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Width across flats S	15 mm
Length l max.	200 mm
Head thickness a max.	12 mm
Depth of crank h max.	24 mm
Head width b max. mm	24 mm

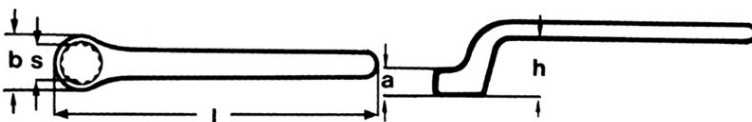

technical change and errors excepted

