

## Product information

# 98 01 18

- Cranked
- Basic tool chrome-plated
- Chrome vanadium steel, forged, oil-hardened

## Box Wrench

IEC 60900 DIN EN 60900




⚡ 1000 V Ⓞ

### General

Article No.	98 01 18
EAN	4003773020288
Weight	210 g
Dimensions	22 x 42 mm
Standard	DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

### Technical details

Width across flats S	18 mm
Length l max.	210 mm
Head thickness a max.	13 mm
Depth of crank h max.	28 mm
Head width b max. mm	29 mm

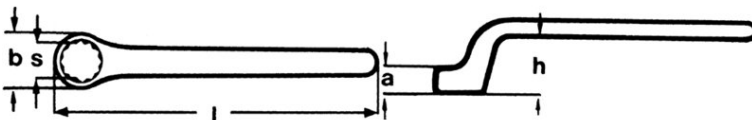

*technical change and errors excepted*

