


KERN 318-07

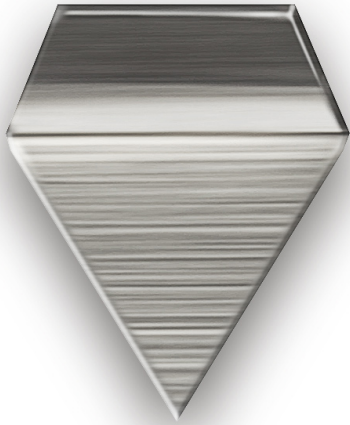

Milligram weights, E2, 100 mg, Platelet, stainless steel polished (OIML)



Services (optional)

Article number for conformity assessment	952-357
Article number for DAkkS calibration	962-357
Article number for guaranteed plus-deviation	921-357

Pictograms

STANDARD



Category

Brand	KERN
Product category	Individual weight
Product group	OIML E2
Product family	318

Measuring System

Conformity assessment possible	✓
Test weight - nominal value	100 mg
Test weight - volume (cm ³)	0,0116
Test weight - volume uncertainty (cm ³)	0,0002
Permissible tolerance according to OIML (+/-)	0,016 mg
Weight OIML class	E2

Construction

Shape weight	Platelet
Dimensions weight (W×D×H)	8,5×8,5×4 mm
Material	stainless steel polished (OIML)

Packing & Shipping

Readability force [d] (N)	1 d
Dimensions packaging (W×D×H)	8,5×8,5×4 mm
Net weight	0,0001 kg
Shipping method	Parcel service
Net weight approx.	0,05 kg
Gross weight approx.	0,05 kg
Shipping weight	0,1 kg