


# KERN 338-06

Milligram weights, F2, 50 mg, Platelet, stainless steel polished (OIML)

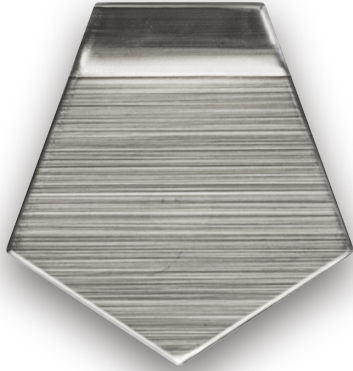

## Services (optional)

Article number for conformity assessment	952-456
Article number for DAkkS calibration	962-456
Article number for guaranteed plus-deviation	921-456

## Pictograms

### STANDARD



## Category

Brand	KERN
Product category	Individual weight
Product group	OIML F2
Product family	338

## Measuring System

Conformity assessment possible	✓
Test weight - nominal value	50 mg
Test weight - volume (cm <sup>3</sup> )	0,0058
Test weight - volume uncertainty (cm <sup>3</sup> )	0,0001
Permissible tolerance according to OIML (+/-)	0,12 mg
Weight OIML class	F2

## Construction

Shape weight	Platelet
Dimensions weight (W×D×H)	7,5×6×3 mm
Material	stainless steel polished (OIML)

## Packing & Shipping

Readability force [d] (N)	1 d
Dimensions packaging (W×D×H)	7,5×6×3 mm
Net weight	0,00005 kg
Shipping method	Parcel service
Net weight approx.	0,05 kg
Gross weight approx.	0,05 kg
Shipping weight	0,1 kg