


KERN AC 03

KERN

Flat jaw attachment for tension tests up to 5 kN (e.g. textile, paper etc.),
clamping width: 4 mm, thread: M6

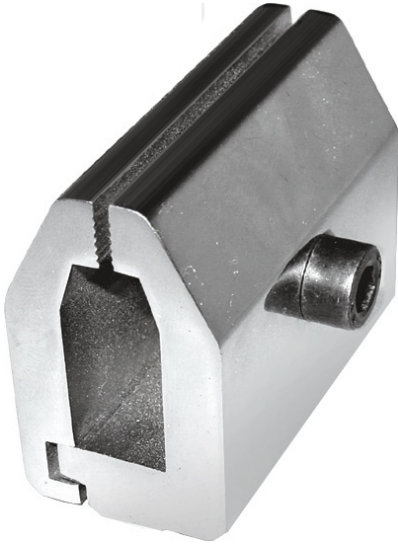

Category

Brand	Sauter
Product category	Measuring instruments
Product group	Clamps

Construction

Dimensions completely mounted (W×D×H)	60×40×25 mm
Material housing	metal
Material	steel
Tensile/compressive force [Max]	5 kN
Mounting - force dissipation	Threaded hole M6

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Readability force [d] (N)	1 d
Shipping method	Parcel service
Dimensions packaging (W×D×H)	150×100×10 mm
Net weight approx.	0,60 kg
Gross weight approx.	0,60 kg
Shipping weight	0,58 kg

Piktograms

STANDARD

