


# KERN FK-A01

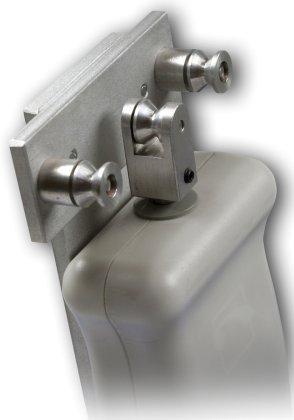

Tensiometer attachment with Safe-insert function: Pull and release to insert the running cable in between the rolls, for tensile strength testing up to 250 N, aluminium attachment, rolls can be adjusted inwards



## Category

Brand	Sauter
Product category	Measurementtechnology

## Construction

Dimensions device (W×D×H)	140×140×40 mm
Dimensions completely mounted (W×D×H)	140×140×40 mm
Material	metal
Material housing	metal

## Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

## Packing & Shipping

Readability force [d] (N)	1 d
Dimensions packaging (W×D×H)	200×100×50 mm
Net weight	0,5 kg
Shipping method	Parcel service
Net weight approx.	0,50 kg
Gross weight approx.	0,55 kg
Shipping weight	0,52 kg

## Pictograms

### STANDARD

