


KERN KFU 600V30M

U-Weighing bridge

KERN

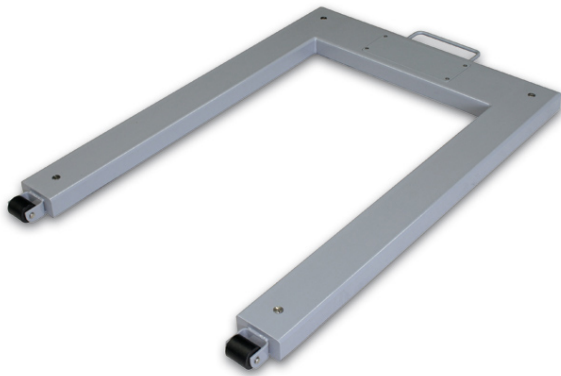

Shipping weight 84 kg

Services (optional)

Article number for conformity assessment	965-230
Article number for DAkkS calibration	963-130

Piktogramme

STANDARD



Category

Brand	KERN
Product category	Measuring Technology Components
Product group	Platforms

Measuring System

Readability [d]	200 g
Weighing capacity [Max]	600 kg
Minimum weight [Min]	4 kg

Approval

Conformity assessment possible ex works	✓
Verification scale interval [e]	200 g

Construction

Dimensions weighing platform (W×D×H)	840×1300×90 mm
Material weighing plate	stainless steel
Material platform	Stainless steel
Cable length	5 m
Allowed cable length display device [Max]	5 m
Levelling feet adjustable	✓
Load cells - number	4

Functions

IP protection - complete device	IP68
---------------------------------	------

Packing & Shipping

Readability force [d] (N)	2 d
Shipping method	Freight
Dimensions packaging (W×D×H)	1380×850×310 mm
Net weight approx.	55 kg
Gross weight approx.	85 kg