


# KERN OBB-A 1259

# KERN

Infinity planachromatic objective lens (without cover glass) for a large working distance, 40 x /0,65, (3,9 mm) (sprung)

## Pictograms

### STANDARD

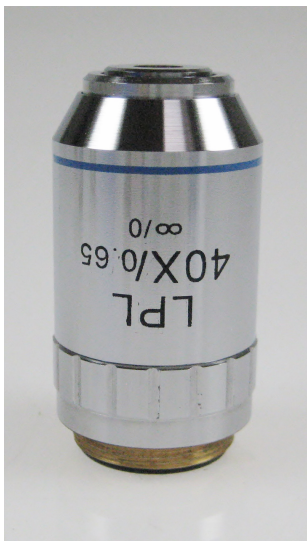

## Category

Brand	Optics
Product category	Optical Instrument
Product group	Microscope objective lens

## Construction

Anti fungus	✓
-------------	---

## Environmental conditions

Storage temperature [Min]	-5 °C
Storage temperature [Max]	40 °C

## Packing & Shipping

Readability force [d] (N)	1 d
Dimensions packaging (W×D×H)	65×40×40 mm
Net weight	0,3 kg
Shipping method	Parcel service
Net weight approx.	0,30 kg
Gross weight approx.	0,60 kg
Shipping weight	0,6 kg

## Objective

Objective quality	Infinity Plan
Objective magnification	40 x
Numerical Aperture	0,65
Objective working distance	3,9 mm