

KERN PES 620-3M



Robust laboratory and industrial precision scale for heavy items



Construction

Dimension housing (W×D×H)	220×330×90 mm
Dimensions rectangular draught shield - inner (W×D×H)	170×150×100 mm
Dimensions rectangular draught shield - outer (W×D×H)	175×155×105 mm
Dimensions weighing surface (W×D)	140×120 mm
Material housing	cast aluminium
Material weighing plate	stainless steel
Material platform	Stainless steel
Material draught shield	plastic
Levelling feet adjustable	✓

Functions

Number of keys for operation	6
Auto-off interval(s) in battery mode/rechargeable battery mode	3 min
Capacity display	✓
Tare function	manual (multi)
Percentage determination	✓
Counting function	✓
Tolerance weighing	✓
Tolerance weighing - type of signal	visual
Standby function	✓
Recipe/summing level	Rez A (Net total)
Sum memory function	✓
Underfloor weighing	Eye (included in delivery)
Interfaces	RS-232 standard Digital I/O (optional, factory)

Counting

Smallest piece weight when piece counting - laboratory conditions	1 mg
Smallest piece weight when piece counting - normal conditions	10 mg
Reference quantity	5, 10, 30, 100
Counting resolution (laboratory conditions)	620.000

Power Supply

Input voltage power supply / power [Max]	220 V - 240 V AC, 50 Hz
Input voltage device / power [Max]	12 V, 1 A
Plug-in power supply type	Power adapter
Supplied plug-in power supply	Power supply unit

Category

Brand	KERN
Product category	Laboratory balances
Product group	Precision balances

Measuring System

Readability [d]	0,001 g
Weighing capacity [Max]	620 g
Eccentric loading at 1/3 [Max]	0,003 g
USP Minimum weight of sample (k = 2, U = 0.1%)	2 g
Reproducibility	0,001 g
Linearity	± 0,003 g
Weighing system	Tuning fork
Resolution	620.000
Units	kg g ct
Default unit	g
Stabilization time	3 s
Warm-up time	4 h
Adjustment options	Adjusting with external weight
Recommended adjusting weight	500 g (E2)

Approval

CE mark	✓
---------	---

Display

Display digit height	14 mm
Display backlight	no
Languages of the user interface	English

KERN PES 620-3M



Robust laboratory and industrial precision scale for heavy items

Plug-in power supply / adapter for countries - included with the delivery	EURO CH
Plug-in power supply / adapter for countries - optional	EURO UK US CH
Rechargeable battery optional	Rchrg. battery optional
Rechargeable battery	PES-A01
Rechargeable battery charging time	15 h
Rechargeable battery operating time - backlight on	6 h
Rechargeable battery operating time - backlight off	32 h

Environmental conditions

Humidity of environment [Max]	80 %
Ambient temperature [Min]	10 °C
Ambient temperature [Max]	30 °C

Packing & Shipping


Readability force [d] (N)	1 d
Shipping method	Parcel service
Dimensions packaging (W×D×H)	335×435×220 mm
Net weight approx.	3,6 kg
Gross weight approx.	6 kg

Services (optional)

Article number for DAkkS calibration	963-103
Article number for certificate of conformity (verification)	969-517

Piktogramme

STANDARD

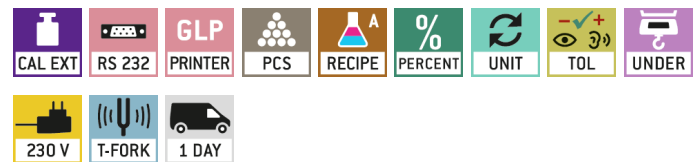

OPTION



FACTORY

