


# KERN TVP

Manual test stand for compressive force measurements

# KERN

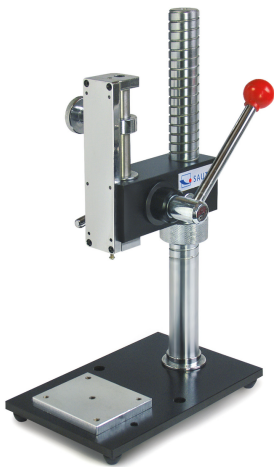

Shipping weight 12 kg

Pictograms

STANDARD



## Category

Brand	Sauter
Product category	Test bench
Product group	Manual test stand
Product family	TVP

## Construction

Dimension (W×D×H)	150×233×420 mm
Dimension housing (W×D×H)	150×233×420 mm
Dimensions completely mounted (W×D×H)	150×233×420 mm
Material housing	metal, lacquered
Generated force [Max]	500 N
Mounting - force application	5 × threaded hole M6
Mounting - force dissipation	5 × threaded hole M6
Measurement alignment	vertical
Type of drive	manual lever
Traverse distance with lever movement / release [Max]	78 mm
Measuring room height [Max]	315 mm

## Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

## Packing & Shipping

Readability force [d] (N)	1 d
Dimensions packaging (W×D×H)	570×275×240 mm
Net weight	10,5 kg
Shipping method	Parcel service
Net weight approx.	11 kg
Gross weight approx.	12 kg