


445.10R Drillzangen 10"**Produktbeschreibung :**

- Automatisches Modell.
- Seitlicher Drahtschneider: Edelstahl, Durchmesser 1 mm.
- 3 Umdrehungen: 125 mm Spannweg.

B [mm]:	30
C [mm]:	11
E [mm]:	2,5
E1 [mm]:	15,5
E2 [mm]:	11,5
E3 [mm]:	19
E4 [mm]:	15,5
H [mm]:	25
H1 [mm]:	40
L [mm]:	360
L1 [mm]:	230
L2 [mm]:	360
[g]:	400

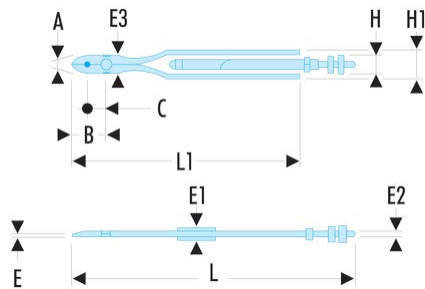