


**445.8R Kurze Drillzangen 8"****Produktbeschreibung :**

- Automatisches Modell.
- Seitlicher Drahtschneider: Edelstahl, Durchmesser 1 mm.
- 2,5 Umdrehungen: 95 mm Spannweg.

B [mm]:	20
C [mm]:	7
E [mm]:	2,5
E1 [mm]:	15
E2 [mm]:	10,5
E3 [mm]:	15
E4 [mm]:	15
H [mm]:	22
H1 [mm]:	37
L [mm]:	215
L1 [mm]:	170
L2 [mm]:	215
[g]:	245

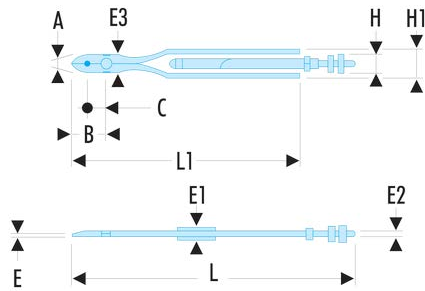