

7515/16 Krafftform Safe-Torque Speed Universal 1, 16 pieces

Series 7500 Krafftform Safe-Torque Speed Torque Screwdrivers -



EAN: 4013288228338
Part number: 05075851001
Article number: 7515/16

Size: 175x125x60 mm
Weight: 609 g
Country of origin: CZ
Customs tariff number: 82079030

 
- Torque screwdriver with quick torque adjustment
- Easy and quick torque setting
- Fixed position (Torque Lock) for unlimited tightening and loosening moments
- Secure slip-over torque function for clockwise/anti-clockwise torque-control
- Quick and easy setting of the selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm)
- For bits with 1/4" external hexagon drive, also suitable for socket wrench inserts via adapter - ideal for bike operations
- Tools with Hex-Plus profile prevent premature rounding of hexagonal socket screws
- Suitable for docking with the Wera 2go system

16-piece tool set. For professional screwdriving/professional fine adjustment AND for torque-controlled screwdriving. Secure slip-over torque mechanism with quick clockwise/counterclockwise setting and five selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm) and one fixed position (Torque Lock) for unlimited loosening and tightening moments. Quick-release holder for high robustness. Suitable for bits with 1/4" external hexagon drive. 15 tough bits (89 mm length).

Web link

https://products.wera.de/en/torque_tools_series_7500_krafftform_safe-torque_speed_torque_screwdrivers_null_7515_16.html


Wera - 7515/16
05075851001 - 4013288228338



Five selectable tightening torques



Torque screwdriver with quick torque adjustment

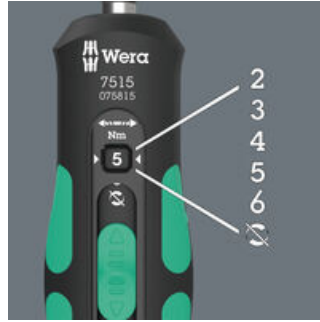

Five selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm) and one fixed position (Torque Lock) for unlimited tightening and loosening moments.

Simple setting



Easy setting of the selectable tightening torques.

Excess-load signal




Distinctly audible and noticeable excess-load signal when the pre-set torque is reached.

Storage and transport



Storage and transport in a robust and compact textile roll bag, so the tool is always close at hand.

Flexible thanks to hook and loop fastener strips

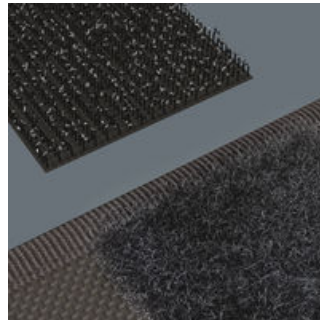

The textile box features a fleece zone at the back. Using the provided self-adhesive hook and loop fastener strips, the textile box can be attached to the Wera 2go components. Or to the wall, shelf or workshop trolley.

Web link

https://products.wera.de/en/torque_tools_series_7500_kraffform_safe-torque_speed_torque_screwdrivers_null_7515_16.html

Wera - 7515/16
05075851001 - 4013288228338

Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

7515/16 Krafftform Safe-Torque Speed Universal 1, 16 pieces

Series 7500 Krafftform Safe-Torque Speed Torque Screwdrivers -




Set contents:

7515 Krafftform Safe-Torque Speed Torque screwdriver, 2-6 Nm, 1/4" x 2.0 Nm x 3.0 Nm x 4.0 Nm x 5.0 Nm x 6.0 Nm x 147.5 mm

05075815001 1x 1/4" x 2.0 Nm x 3.0 Nm x 4.0 Nm x 5.0 Nm x 6.0 Nm x 147.5 mm




851/4 Z bits, PH 2 x 89 mm

 05059775001 1x PH 2 x 89 mm




867/4 Z TORX® B0 bits with bore hole, TX 10 x 89 mm

 05060050001 1x TX 10 x 89 mm
05060051001 1x TX 15 x 89 mm
05060052001 1x TX 20 x 89 mm
05060053001 1x TX 25 x 89 mm
05060054001 1x TX 30 x 89 mm




867/4 IP TORX PLUS® bits, 10 IP x 89 mm

 05134671001 1x 10 IP x 89 mm
05134672001 1x 15 IP x 89 mm
05134673001 1x 20 IP x 89 mm
05134674001 1x 25 IP x 89 mm
05134676001 1x 30 IP x 89 mm



840/4 Z bits, 3 x 89 mm

 05059630001 1x 3 x 89 mm
05059631001 1x 4 x 89 mm
05059632001 1x 5 x 89 mm
05059633001¹⁾ 1x 6 x 89 mm



1) Hexagonal blade

Web link

https://products.wera.de/en/torque_tools_series_7500_krafftform_safe-torque_speed_torque_screwdrivers_null_7515_16.html

Wera - 7515/16
05075815001 - 4013288228338

Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de