

9630 Magnetic rail 6000 Joker 1 Ratcheting combination wrenches set, 11 pieces

6000 Joker Ratcheting combination wrenches



EAN:	4013288228949	Size:	380x165x45 mm
Part number:	05020014001	Weight:	1980 g
Article number:	9630	Country of origin:	CZ
		Customs tariff number:	82041100

- 11-piece set
- With its strong magnet, the rail holds securely to metal surfaces. It can also be bolted to the wall.
- The clips hold the tools perfectly
- Practical holding function thanks to the metal plate in the jaw
- Limit stop prevents any slipping
- The double-hex geometry reduces the risk of slipping
- Return angle of only 30°
- With Take it easy tool finder: colour coding by size

The Joker 6000 ring ratchet spanner with holding function for hexagon screw heads and bolts. With its extra hard teeth, the exchangeable metal plate in the open end secures screws and sockets. The integrated end stop can prevent the screw head from slipping down and allows application of high torques. The double hexagon geometry ensures a positive connection with the screw or bolt and thus reduces the risk of slipping. A return angle of only 30° at the open end avoids time-consuming rotating of the wrench whilst screwdriving. Ratchet mechanism at the ring side with exceptionally high fine toothing of 80 teeth for flexibility even in confined spaces. The specially engineered geometry allows high torque transmission and high bending stiffness. Made of high-performance chromium molybdenum steel with nickel-chromium coating for high corrosion protection. With "Take it easy" Tool finder: Colour coding by size. The clips hold the tools perfectly. With its strong magnet, the rail holds securely to metal surfaces. It can also be bolted to the wall.



Web link

https://products.wera.de/en/joker_6000_joker_ratcheting_combination_wrenches_9630.html

Wera - 9630
05020014001 - 4013288228949


Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

6000 Joker Ratcheting combination wrenches

Secure tool holding




With its strong magnet, the rail can be attached securely to metal surfaces.

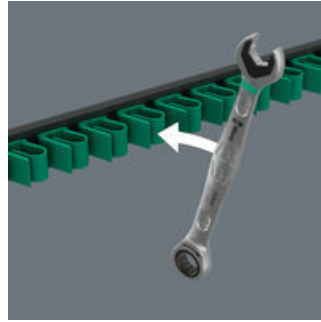

The high-quality aluminium magnetic rail offers space for up to 11 spanners. The clamping springs hold the tools securely.

Held by magnetic force

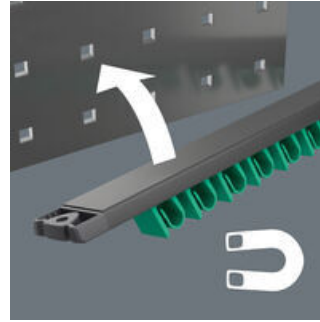

With its strong magnet, the rail can be attached securely to metal surfaces.

Screw mounting




The rail can also be bolted to the wall.

Ring ratchet spanner Joker 6000



The Joker's holding function means that nuts and bolts can be held in the jaw and easily positioned where they are needed. Fastening on to the thread can then be done quickly and safely, thanks to the innovative special stop-plate which holds the fastener. No more time-wasting searches for dropped nuts and bolts! After applying and positioning the nut or bolt, fastening can begin immediately - no additional tools required.

Integrated limit-stop

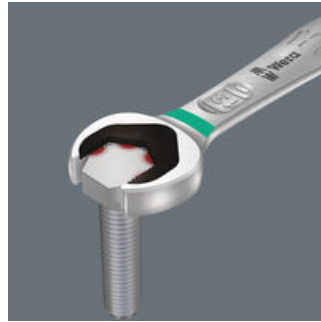


Constant re-positioning of the wrench? Difficulty holding fasteners in confined spaces? Easing off to avoid any risks of injury or fastener damage? That was yesterday. Today, the Joker prevents slipping off of the fastener head with its integrated limit-stop - no longer is the thumb needed to act as a depth stop. This makes applications much easier and allows significantly more force to be applied during fastening jobs.

Double-hex geometry



The Joker's clever double-hex geometry delivers a very positive connection with nuts or bolts - it's a perfect fit. And the exchangeable, hardened metal gripping plate in the Joker's open end literally bites itself into the bolt, with its extremely hard tips. Both features combine to prevent slipping, even at higher torque.

Small return angle

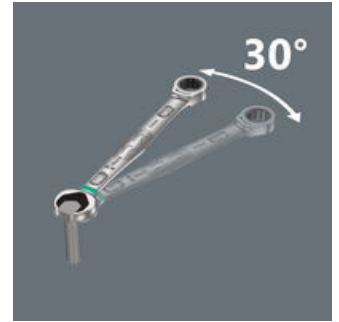

Instead of 60°, the Joker only has a 30° back-pivoting angle thanks to its unique double-hex design. Along with the Joker's straight neck, this means that flipping the wrench has become a thing of the past. With the Joker, you can now loosen and tighten nuts and bolts, in situations where conventional tools fail. Particularly in confined spaces, where conventional open-jawed wrenches cannot be used. The combination of limit stop and small return angle enables effective work, even on screw pipe connections.

Web link

https://products.wera.de/en/joker_6000_joker_ratcheting_combination_wrenches_9630.html

Wera - 9630
05020014001 - 4013288228949

Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

9630 Magnetic rail 6000 Joker 1 Ratcheting combination wrenches set, 11 pieces

6000 Joker Ratcheting combination wrenches




Set contents:

6000 Joker Ratcheting combination wrenches, 13 x 177 mm



05073273001	1x	13 x 177 mm
05073277001	1x	17 x 224 mm
05073279001	1x	19 x 246 mm
05073268001	1x	8 x 144 mm
05073271001	1x	11 x 165 mm
05073272001	1x	12 x 170.7 mm
05073274001	1x	14 x 188 mm
05073275001	1x	15 x 200 mm
05073276001	1x	16 x 212 mm
05073278001	1x	18 x 235 mm
05073270001	1x	10 x 159 mm

9610 Joker Magnetic rail, for up to 11 spanners, empty, 30 x 370 mm

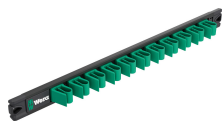

05136413001	1x	30 x 370 mm
-------------	----	-------------

Web link

https://products.wera.de/en/joker_6000_joker_ratcheting_combination_wrenches_9630.html

Wera - 9630

05020014001 - 4013288228949

Wera Werkzeuge GmbH

Korzter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de