


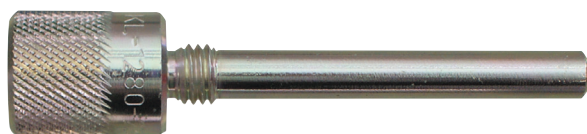


KL-1280-701

Locking Tool Set, Renault



Product information EN
⚠ Read and understand before use!

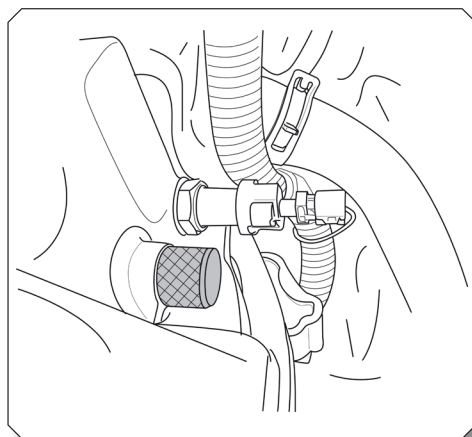

www.gedore-automotive.com



GEDORE Automotive GmbH

Breslauer Straße 41
78166 - Donaueschingen
Postfach 1329
78154 Donaueschingen - GERMANY

☎ +49 (0) 771 / 8 32 23-0
☎ +49 (0) 771 / 8 32 23-90
✉ info.gam@gedore.com
🌐 gedore-automotive.com

GEDORE TOOLS, INC.

Only for USA, Canada & Mexico / Sólo para EE.UU., Canadá y México
Seulement pour les USA, le Canada et le Mexique
7187 Bryhawke Circle, Suite 700
North Charleston, SC 29418, USA

☎ +1-843 / 225 50 15
☎ +1-843 / 225 50 20
✉ info@gedoretools.com
🌐 gedore.com

Version 05/2022

1280-701_EN220511.indd

Product description


KL-1280-701 - Locking tool set, Renault

Applicable to Dacia, Nissan, Opel/Vauxhall, Renault, Suzuki and Mercedes 1.5 and 2.8 litre Diesel engines as fitted to: Renault Clio II / III, Fluence, Kangoo I / II, Laguna III, Logan, Mascott, Master II / Propulsion / RWD, Megane II / III, Modus I / II, Scenic I / II, Twingo II; Opel/Vauxhall Movano-A; Dacia Duster, Logan / MCV / Pick-up / Van; Nissan Cube, Juke, Kubistar, Micra, Note, NV200, Qashqai, Tiida; Suzuki Jimny; Mercedes A-Class, B-Class, Citan, CLA.

(Engine codes: K9K, K9K262, K9K 266, K9K 299, K9K 700, K9K 702, K9K 704, K9K 706, K9K 710, K9K 712, K9K 714, K9K 716, K9K 718, K9K 722, K9K 724, K9K 728, K9K 729, K9K 732, K9K 740, K9K 750, K9K 752, K9K 760, K9K 762, K9K 764, K9K 766, K9K 768, K9K 770, K9K 772, K9K 774, K9K 780, K9K 782, K9K 790, K9K 792, K9K 794, K9K 796, K9K 800, K9K 802, K9K 804, K9K 806, K9K 808, K9K 830, K9K 832, K9K 834, K9K 836, K9K 837, K9K 838, K9K 842, K9K 846, K9K 884, K9K 892, K9K 894, K9K 896, K9K 898; S9W 206, S9W 208, S9W 212, S9W 700, S9W 702, 607.951)

Designed for the locking/positioning of engine shafts such as camshaft, crankshaft, injection pump and flywheel. An indispensable tool set when changing a timing belt or performing an engine repair.

EN

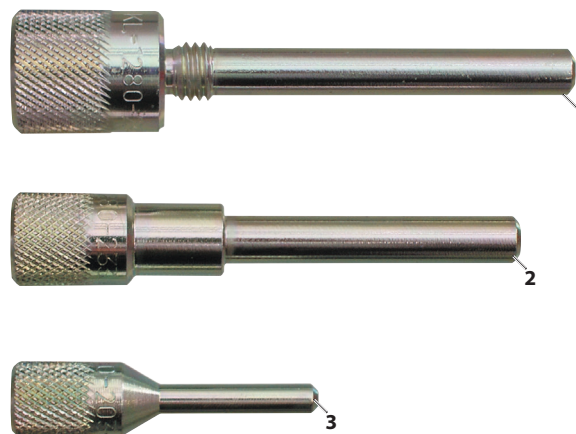

Scope of delivery/Component overview

Pos.	Part No.	Description	Qty	Alternative Tool No.
1	KL-1280-233 B	Locking pin, Ø 7.9/11.9mm	1	09912-46510, 09919-58120, W 607 589 01 15 00, 99395214, mandrel Ø 8mm, KM-6031, KM-6130, KV113B0110, KV113B0280, Mot.1054, Mot.1430, Mot.861
2	KL-1280-234 B	Locking pin, M10/Ø 7.9mm	1	09919-58110, W 607 589 00 15 00, KV113B0130, Mot.1489
3	KL-1280-203 A	Locking pin, Ø 4.9mm	1	1.860.617.000, A60617, KM-966, KM-966-2, Mot.910, Mot.910/1
-	KL-4990-2002	Plastic storage box	1	

⚠ Safety instructions and regulations!

- ✔ **Before using** the special tool, read and understand **all** warning and safety instructions and **follow** them for **safe use!**
- ✔ Work on electrical installations may **only** be carried out by appropriately **qualified personnel!**
- ✔ **Always** observe and adhere to **all** safety rules and regulations when working on electrical installations!
- ✔ Use the special tool **as intended**, and **always** carry out maintenance and repair work in compliance with the regulations on occupational safety and accident prevention as well as the vehicle manufacturer's instructions!
- ✔ **Before each use**, check the special tool **carefully** for damage, loose parts, or unauthorised modifications. **Never** use it if you notice any such deficiencies!
- ✔ **Always** wear your personal protective equipment (such as safety goggles, protective gloves, safety shoes) during work!