



KL-4999-820 / -8200

Assembly Trolley "MODULO 820 for Commercial Vehicles",
incl. Hydraulic Cylinder



Product information EN
⚠ Read and understand before use!

www.gedore-automotive.com



GEDORE Automotive GmbH

Breslauer Straße 41
78166 - Donaueschingen
Postfach 1329
78154 Donaueschingen - GERMANY

☎ +49 (0) 771 / 8 32 23-0
☎ +49 (0) 771 / 8 32 23-90
✉ info.gam@gedore.com
🌐 gedore-automotive.com

GEDORE TOOLS, INC.

Only for USA, Canada & Mexico / Sólo para EE.UU., Canadá y México
Seulement pour les USA, le Canada et le Mexique
7187 Bryhawke Circle, Suite 700
North Charleston, SC 29418, USA

☎ +1-843 / 225 50 15
☎ +1-843 / 225 50 20
✉ info@gedoretools.com
🌐 gedore.com

Version 07/2022

4999-820_EN220525.indd

PRODUCT DESCRIPTION KL-4999-820 - Assembly trolley "MODULO 820"

Universally applicable for repairs on wheel bearings, steering and axle systems on commercial vehicles, buses, construction machinery, agricultural machinery, trailers, and semi-trailers.

① The assembly trolley - **KL-4999-8200** does not include the 28t hydraulic cylinder - **KL-0040-2800** in its scope of supply!

Content

- Various drive parts required for operating the tool kits such as, for example, the 28t hydraulic cylinder - **KL-0040-2800**, adapters for hydraulic cylinder, suitable pulling/thrust spindles (M20 + M24) with thrust nut (M24), and quick release nut (M20).
- Various hand tools such as, for example, a 3/4" set of sockets with reversing ratchet, T-handle, extensions (200 + 400mm), and hexagonal sockets (22, 24, 27, 30, 32, 36, 38, 41, 46mm), as well as a ring-fork spanner set XL extra long (10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 24, 27, 30, 32, 36, 41mm), 3/4" screwdriver insert (inner hexagon: 14mm), and a metalworker's hammer 1.5kg.
- Wheel hub puller kit - **KL-1005-100 A** to pull off tight-fitting wheel hubs (with removable hub caps), for example, on BPW, SAF, and ZF axle systems with a hole circle diameter of 8x275mm and 10x335mm.
- Wheel hub puller for compact bearings - **KL-1005-110** for pulling tight-fitting wheel hubs (with detachable hub cap), for example, on axle systems with a hole circle diameter of 10x120, 10x122, 10x143, 10x165, 10x168, 10x225, 12x144, 12x145, 12x164, 12x168, 14x138, 14x144.
- Press frame 28 tonnes - **KL-1039-111** for pressing in and out different bushings, bearings, or bolts directly on the vehicle, for example on extension arms, tippers, dumping tippers, lifting arms, hook lift systems, chassis parts, and many more.
- Ball joint breaker kit (with 6 forks) - **KL-0165-3 A** for breaking ball joint connections, for example on axle and steering systems.
- Loosening tool for tie rod end - **KL-0169-82** for unscrewing and inserting tie sluggish rod ends; for example, for track adjustments and when replacing the tie rod end.
- Various kits from the **KL-1010-..** Silent block puller series for removal and installation of slotted and closed silent blocks (Ø 60 + 65mm) directly on the vehicle, for example, on leaf springs and bearing brackets.
- Wheel hub lifting tool - **KL-1029-300** for lifting heavy-weight wheel hubs without the help of a second person, but using a workshop crane.
- Impact double hexagon spanner SW24 - **KL-1070-1224** for unscrewing tight-fitting brake calliper fittings with SK profile on BPW and SAF axes.

Assembly trolley specifications

- Dimensions H 985 x W 1200 x D 635mm
- Beech multiplex worktop, 30mm thick, oiled
- Total load carrying capacity: 1000kg / mobile operation: 750kg
- 2 fixed castors Ø 200mm and 2 swivel castors Ø 125mm with total brake
- Steel sheet, corrosion-resistant, scratch-resistant powder-coated in GEDORE blue
- Extra wide drawers W 998 x D 474mm with full extension, can be loaded up to 70kg
- Automatic drawer retraction with single pull-out stop and central locking system
- Side walls with Euro perforation 10 x 38mm for fastening hooks and tools


⚠ Safety instructions and regulations!

- ✔ **Before using** the special tool, read, understand, and observe the relevant instructions for **safe use!**
- ✔ Use the special tool **as intended** and **always** carry out maintenance and repair work in compliance with the regulations on occupational safety and accident prevention as well as the vehicle manufacturer's instructions!
- ✔ **Before each use**, check the special tool **carefully** for damage, loose parts, or unauthorised modifications. **Never** use it if you notice any such deficiencies!
- ✔ **Always** wear your personal protective equipment (*such as safety goggles, protective gloves, safety shoes*) during work!

Rolling workbench, 6 drawers (empty) - 1507 XL 40200




Drawer insert A

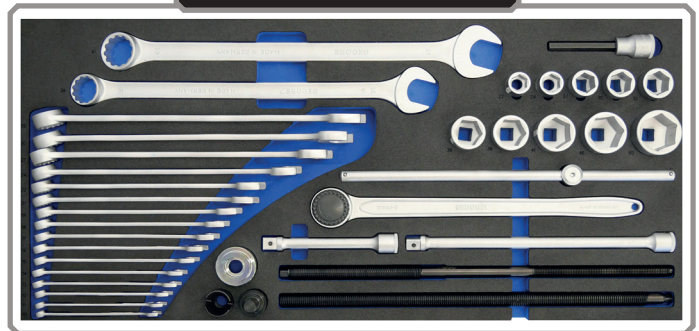


EN

Drawer insert B

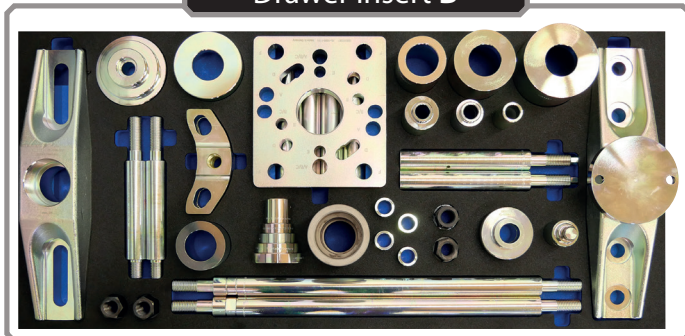

Drawer insert C

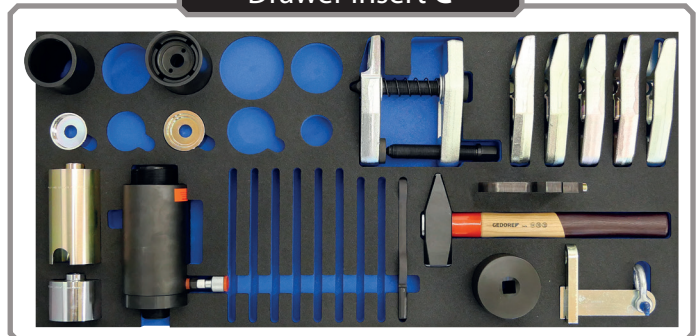

Depending on the application, follow the corresponding instructions!

Depending on the application and the special tool, the corresponding instructions **must** be taken to hand, read, understood, and observed beforehand!

The following instructions and product information are enclosed with the assembly trolley:

KL-0040-2800 - Hydraulic cylinder, 28t

KL-1005-100 A - Wheel hub puller set for commercial vehicles

KL-1005-110 - Wheel hub puller for commercial vehicles

KL-1039-111 - Commercial vehicle press frame 28t

KL-0165..Series - Ball joint puller, series

KL-0169-82 - Track rod end removal socket

KI-1010-..Series - Pulling device for silent blocks on commercial vehicles

KL-1029-300 - Wheel hub lifting tool for commercial vehicles

KL-1070-12/..Series - Impact spanner set, 12-edge profile

Drawer insert A

⚠ Depending on the application, follow the corresponding special instructions for the special tool!




Scope of delivery:

Item	Part no.	Description	Qty.
1	7 XL 10	Ring-fork spanner extra long UD profile, 10mm	1
2	7 XL 11	Combination spanner extra long, UD profile, 11mm	1
3	7 XL 12	Combination spanner extra long, UD profile, 12mm	1
4	7 XL 13	Combination spanner extra long, UD profile, 13mm	1
5	7 XL 14	Combination spanner extra long, UD profile, 14mm	1
6	7 XL 15	Combination spanner extra long, UD profile, 15mm	1
7	7 XL 16	Combination spanner extra long, UD profile, 16mm	1
8	7 XL 17	Combination spanner extra long, UD profile, 17mm	1
9	7 XL 18	Combination spanner extra long, UD profile, 18mm	1
10	7 XL 19	Combination spanner extra long, UD profile, 19mm	1
11	7 XL 21	Combination spanner extra long, UD profile, 21mm	1
12	7 XL 22	Combination spanner extra long, UD profile, 22mm	1
13	7 XL 24	Combination spanner extra long, UD profile, 24mm	1
14	7 XL 27	Combination spanner extra long, UD profile, 27mm	1
15	7 XL 30	Combination spanner extra long, UD profile, 30mm	1
16	7 XL 32	Combination spanner extra long, UD profile, 32mm	1
17	7 XL 36	Combination spanner extra long, UD profile, 36mm	1
18	7 XL 41	Combination spanner extra long, UD profile, 41mm	1
19	KL-0039-2120-2	Quick-release nut M20	1
20	KL-0040-2812-5	Thrust nut M24, Ø 20.5mm	1

Item	Part no.	Description	Qty.
21	KL-0039-1003	Adapter for hydraulic cylinder	1
22	KL-0040-2812-1	Pulling/thrust spindle, M24 x 590	1
23	KL-0040-2846-1 A	Pulling spindle, M20 x 550	1
24	3290-8	VDE extension 3/4", 200mm	1
25	3290-16	VDE extension 3/4", 400mm	1
26	3293 U-2	Reversible ratchet, 3/4"	1
27	3287	Transverse handle 3/4"	1
28	32 22	Socket 3/4", Hexagonal, 22mm	1
29	32 24	Socket 3/4", Hexagonal, 24mm	1
30	32 27	Socket 3/4", Hexagonal, 27mm	1
31	32 30	Socket 3/4", Hexagonal, 30mm	1
32	32 32	Socket 3/4", Hexagonal, 32mm	1
33	32 36	Socket 3/4", Hexagonal, 36mm	1
34	32 38	Socket 3/4", Hexagonal, 38mm	1
35	32 41	Socket 3/4", Hexagonal, 41mm	1
36	32 46	Socket 3/4", Hexagonal, 46mm	1
37	32 50	Socket 3/4", Hexagonal, 46mm	1
38	IN 32 L 14-155	Screwdriver bit 3/4", long Hexagon socket, 14mm	1
KL-4999-8209-1 - Foam insert for drawer			

Drawer insert B

⚠ Depending on the application, follow the corresponding special instructions for the special tool!

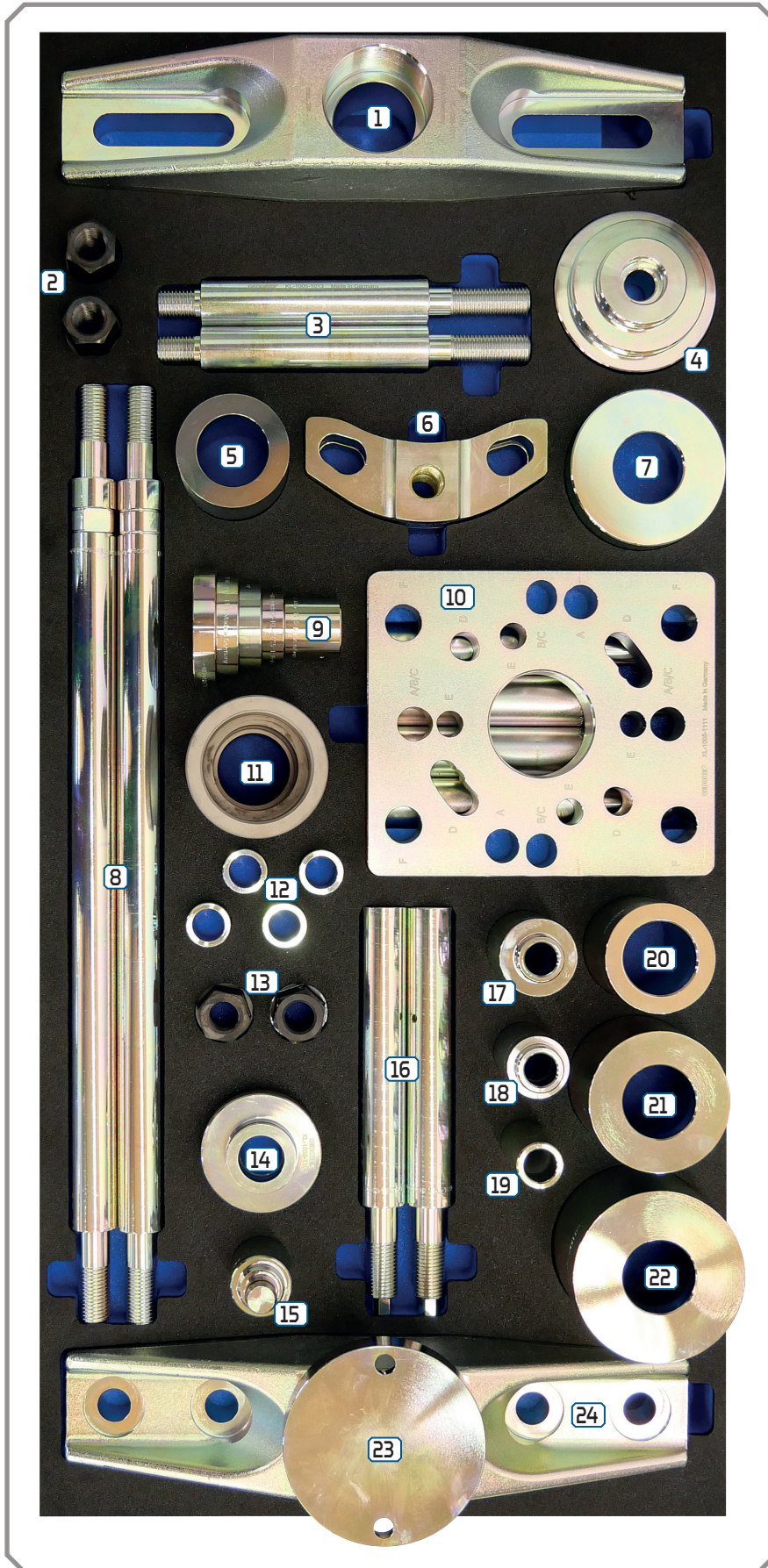


Scope of delivery:

Item	Part no.	Description	Qty.
1	KL-1005-1011	Base plate 2¾"-16 UN	1
2	KL-1005-1014	Hex collar nut M22	2
3	KL-1005-1013	Pull rod M22	2
4	KL-1005-1021	Thrust piece (universal)	1
5	KL-1005-1023	Thrust/support sleeve, long, Ø 73/59mm (SAF axle)	1
6	KL-1005-1012 A	Base M22	2
7	KL-1005-1022	Pressure/support sleeve, short, 103/90mm (ZF axle)	1
8	KL-1039-1102	Pull rod M22	2
9	KL-1005-1119	Thrust disc, Ø 78mm	1
	KL-1005-1118	Thrust disc Ø 68mm	1
	KL-1005-1117	Thrust disc Ø 58mm	1
	KL-1005-1116	Thrust disc, Ø 48mm	1
	KL-1005-1115	Thrust piece, short	1
10	KL-1005-1111	Adapter plate	1
	KL-1005-1113	Adapter spindle low-loader M22x1.5	4

Item	Part no.	Description	Qty.
11	KL-1005-1112	Extension 2 ¾"	1
12	KL-1005-1114	Intermediate sleeve	4
13	KL-1005-1014	Hex collar nut M22	2
14	KL-1039-1105	Adapter 2¾"-16 UNS to Ø 30mm	1
15	KL-1039-1106	Extension for thrust nut M24	1
16	KL-1039-1103	Extension for pull rod M22	2
17	KL-0039-1750	Pressure/support sleeve, long, Ø 50/42mm	1
18	KL-0039-1740	Pressure/support sleeve, long, Ø 40/32mm	1
19	KL-0039-1730	Pressure/support sleeve, long, Ø 30/22mm	1
20	KL-0039-1770	Pressure/support sleeve, long, Ø 70 / 62mm	1
21	KL-0039-1790	Pressure/support sleeve, long, Ø 90 / 82mm	1
22	KL-1039-7110	Pressure/support sleeve, long, Ø 110/102mm	1
23	KL-1039-1107	Bearing base	1
24	KL-1039-1101	Base plate 2¾"-16 UN	1
KL-4999-8209-3 - Foam insert for drawer			

Drawer insert C

⚠ Depending on the application, follow the corresponding special instructions for the special tool!

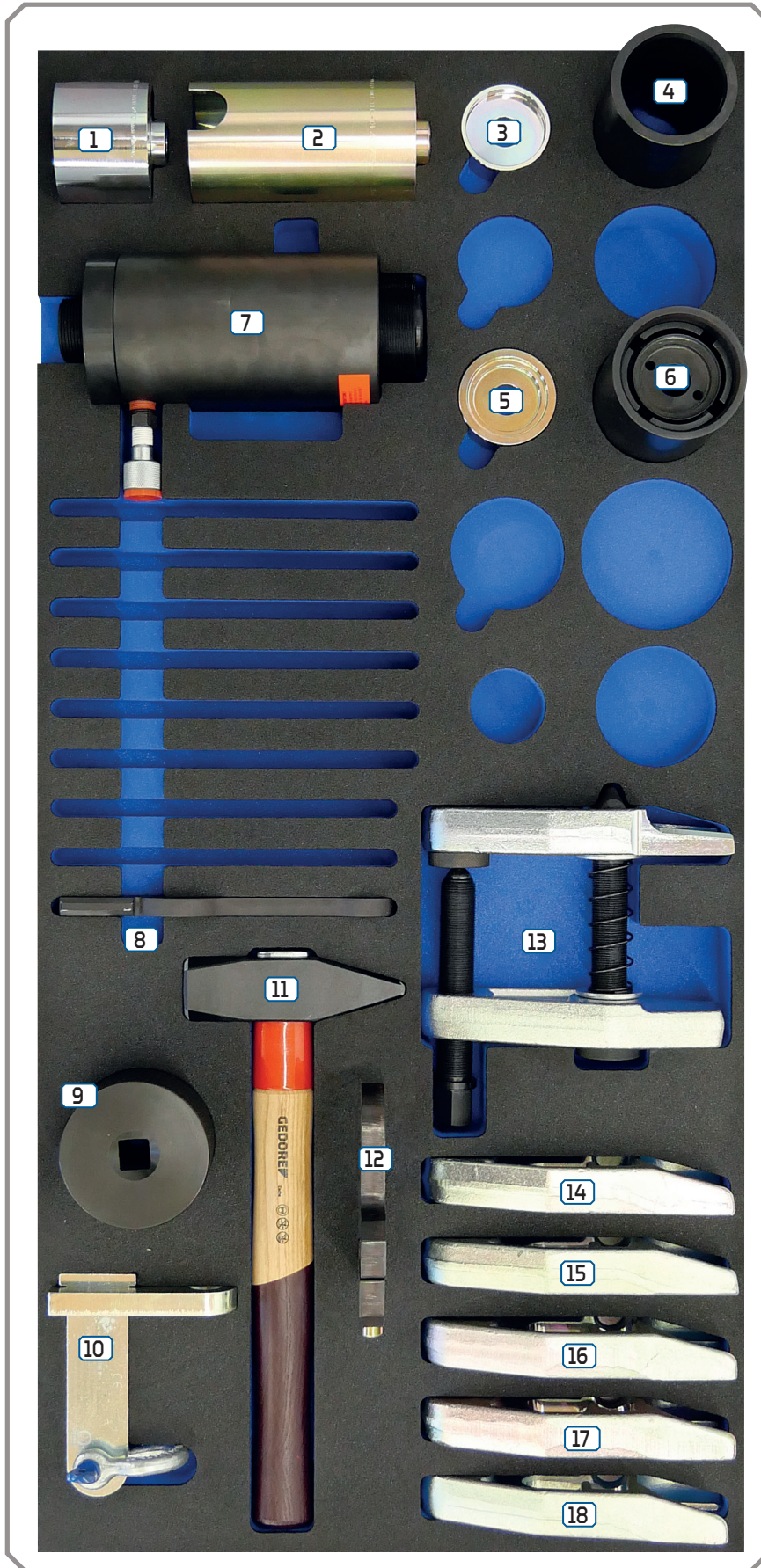

Scope of delivery:

Item	Part no.	Description	Qty.
1	KL-1010-1006	Support sleeve, short, Ø 70mm	1
2	KL-1010-1001	Support sleeve, long, Ø 70mm	1
3	KL-1010-1205	Thrust piece, diameter when removed 60mm	1
4	KL-1010-1201	Conical sleeve, 60mm diameter	1
5	KL-1010-1406	Thrust piece, diameter when removed 65mm	1
6	KL-1010-1401	Conical sleeve, Ø 65mm	1
	KL-1010-1402 A	Resilient thrust piece, Ø 65mm	1
7	KL-0040-2800 M	Hydraulic cylinder 28t	1
	KL-0040-2520	Adapter 3/8" NPT to 1/4" NPT	1
	KL-0215-322	Coupling half (cylinder side)	1
8	KL-1070-1224	Impact spanner, 12-edge profile, SW24	1
9	KL-0169-82	Loosening tool for tie rod end	1

Item	Part no.	Description	Qty.
10	KL-1029-300	Wheel hub lifting tool for commercial vehicles	1
11	600 E-1500	ROTBAND-PLUS metalworker's hammer, with ash wood handle, 1,500 g	1
12	KL-0169-81	Track rod spanner SW34	1
13	KL-0165-300	Basic tool without fork	1
	KL-0165-3501	Fork, size 3, 33mm	1
14	KL-0165-3401	Fork, 47mm	1
15	KL-0165-3301	Fork, 42mm	1
16	KL-0165-3201	Fork, 40mm	1
17	KL-0165-3101	Fork, 34mm	1
18	KL-0165-3001	Fork, 30mm	1
KL-4999-8209-2 - Foam insert for drawer			

GEDORE-Werkzeugfabrik GmbH & Co. KG

Remscheider Straße 149
42899 - Remscheid
Postfach 120361
47873 Remscheid
GERMANY

Vertrieb DEUTSCHLAND

☎ +49 (0) 2191 / 596-0
☎ +49 (0) 2191 / 596-230
✉ info@gedore.com
🌐 www.gedore.com

Sales INTERNATIONAL

☎ +49 (0) 2191 / 596-910
☎ +49 (0) 2191 / 596-911
✉ info@gedore.com
🌐 www.gedore.com

GEDORE TOOLS, INC.

Only for USA, Canada & Mexico
Sólo para EE.UU., Canadá y México
Seulement pour les USA, le Canada et le Mexique
7187 Bryhawke Circle, Suite 700, North Charleston, SC 29418, USA

☎ +1-843 / 225 50 15
☎ +1-843 / 225 50 20
✉ info@gedoretools.com
🌐 www.gedoretools.com

Worldwide GEDORE service centers and offices are listed on the Internet at: www.gedore.com

GEDORE Automotive GmbH

Breslauer Straße 41
78166 - Donaueschingen
Postfach 1329
78154 Donaueschingen
GERMANY

Vertrieb DEUTSCHLAND

☎ +49 (0) 771 / 8 32 23-0
☎ +49 (0) 771 / 8 32 23-90
✉ info.gam@gedore.com
🌐 gedore-automotive.com



www.gedore-automotive.com