

Kraftform Kompakt Turbo i 1 Tool finder, 16 pieces

Kraftform Kompakt Turbo



EAN:	4013288230041	Size:	210x130x80 mm
Part number:	05006640001	Weight:	803 g
Article number:	Kraftform Kompakt Turbo i 1 Tool Finder	Country of origin:	CZ
		Customs tariff number:	82054000

- 4 times the screwdriving speed thanks to the turbo function (purely mechanical - without battery)
- Activate and deactivate the turbo function by a simple push of a button
- Turbo function especially for smooth couplings
- Can be used without the turbo function like a normal screwdriver for couplings with steadily increasing torque
- Robust, maintenance-free gear made of steel
- VDE blades (157 mm length) with practical spinning function, anti-roll protection and "Take it easy" Tool finder: Colour coding by profile and laser-engraved size indication
- Reduced blade diameter with integrated protective insulation for lower-lying screws
- Individually tested tool as per IEC 60900 at 10,000V

Many users wish to carry out screwdriving operations faster without compromises. With a screwdriver which is precise, allows powerful end screwdriving and is also much faster than a conventional screwdriver. The solution: A planetary drive that can be switched on and off: Integrated in the handle it quadruples the working speed in smooth couplings all mechanically. One hand holds the front part of the handle, the second hand turns the back part of the handle. The turbo function can be switched on and off at the push of a button. Turning it off is recommended for tightening and loosening with high torque as well as for fine adjustments. Robust, maintenance-free steel drive with maximum torque of 14 Nm when the turbo function is deactivated. In the VDE version, the 827 T i Kraftform Turbo bitholding screwdriver with the Wera VDE blades individually tested as per IEC 60900 ensures fast and safe working even under tension (up to 1,000 volt). VDE blades with "Take it easy" Tool finder: Colour coding by profile and laser-engraved size indication - for quick and easy identification of the required tool. In a robust belt pouch. The textile box features a fleece zone at the back. Using the provided self-adhesive hook and loop fastener strips, the textile box can be attached to the Wera 2go components. Or to the wall, shelf or workshop trolley.

Web link

https://products.wera.de/en/kraftform_kompakt_kraftform_kompakt_turbo_kraftform_kompakt_turbo_i_1_tool_finder.html


Wera - Kraftform Kompakt Turbo i 1 Tool Finder
05006640001 - 4013288230041



Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Kraftform Kompakt Turbo

Faster screwdriving

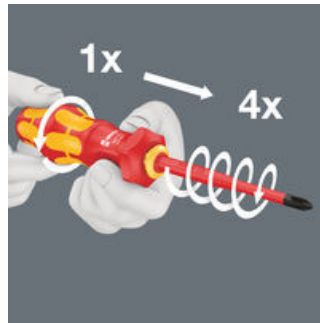


The construction of the Kraftform Turbo allows the speed of manual screwdriving to be quadrupled, especially for smooth couplings - without electricity!

Robust, maintenance-free gear made of steel



The robust steel design is maintenance-free and ensures a long product life.

Handle/interchangeable blade system

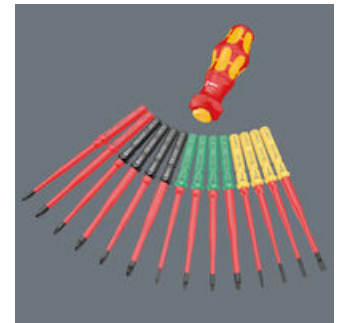

With its 9 mm mounting, the Kraftform Turbo is suitable for all Wera Kraftform Kompakt VDE interchangeable blades. The "holder/interchangeable blade system" stands for flexible working with many screw profiles.

Individually tested




The individual testing at 10,000 volts, in accordance with IEC 60900, ensures safe working with loads up to 1,000 volts.

With and without Turbo



The turbo function can be switched on or off at the push of a button. Turning it off is recommended for tightening and loosening with high torque as well as for fine adjustments.

VDE interchangeable blade with reduced shaft diameter

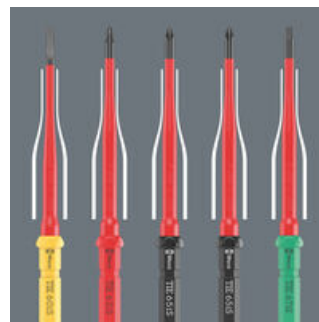

Reduced blade diameter with integrated protective insulation, allows sunken screws and spring elements to be accessed and actuated, individually tested as per IEC 60900.

PlusMinus screwdrivers



For the use in terminal blocks, control cabinets, switches, relays, sockets etc.

Web link

https://products.wera.de/en/kraftform_kompakt_kraftform_kompakt_turbo_kraftform_kompakt_turbo_i_1_tool_finder.html

Wera - Kraftform Kompakt Turbo i 1 Tool Finder
05006640001 - 4013288230041


Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Kraftform Kompakt Turbo i 1 Tool finder, 16 pieces

Kraftform Kompakt Turbo


Set contents:

827 T i Kraftform Turbo blade-holding handle, 9 x 125 mm

 05057481001 1x 9 x 125 mm




817 VDE Kraftform blade-holding handle, 9 x 98 mm

 05003990001 1x 9 x 98 mm




Kraftform Kompakt VDE 62 iS Take it easy, PH 1 x 157 mm

 05006512001 1x PH 1 x 157 mm
05006513001 1x PH 2 x 157 mm




Kraftform Kompakt VDE 65 iS Take it easy, PZ 1 x 157 mm

 05006526001 1x PZ 1 x 157 mm
05006527001 1x PZ 2 x 157 mm




Kraftform Kompakt VDE 65 iS PZ/S Take it easy, # 1 x 157 mm

 05006530001 1x # 1 x 157 mm
05006531001 1x # 2 x 157 mm




Kraftform Kompakt VDE 67 i TORX® Take it easy, TX 10 x 157 mm

 05006534001 1x TX 10 x 157 mm




Kraftform Kompakt VDE 67 iS TORX® Take it easy, TX 15 x 157 mm

 05006540001 1x TX 15 x 157 mm
05006541001 1x TX 20 x 157 mm
05006542001 1x TX 25 x 157 mm




Kraftform Kompakt VDE 60 i Take it easy, 0.4 x 2.5 x 157 mm

 05006500001 1x 0.4 x 2.5 x 157 mm



 
Kraftform Kompakt VDE 60 iS Take it easy, 0.6 x 3.5 x 157 mm

 05006506001 1x 0.6 x 3.5 x 157 mm
05006507001 1x 0.8 x 4 x 157 mm
05006508001 1x 1 x 5.5 x 157 mm



Hook and Loop Fastener Strip 120, 120 x 50 mm

1x 120 x 50 mm



Web link

https://products.wera.de/en/kraftform_kompakt_kraftform_kompakt_turbo_kraftform_kompakt_turbo_i_1_tool_finder.html

Wera - Kraftform Kompakt Turbo i 1 Tool Finder
05006640001 - 4013288230041

Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de