


525-100 Parallel vice with jaw width, 17 mm jaw height, up to 125 mm clamping range (Blue)

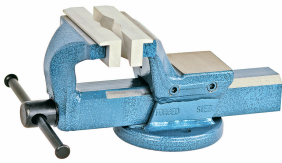

DETAIL IMAGE



DESCRIPTION

The parallel vices of the 525 series are used for clamping workpieces in crafts, industry, and workshops. The induction-hardened parts of the 525 series make it ideal for universal clamping of medium-sized workpieces, and the material ensures the necessary durability and stability of the vice.

RANGE OF APPLICATION

For clamping workpieces

BENEFIT

- High-quality material and simple operation
- Medium design for flexible work as a parallel vice
- Available in the colours Blue, Red and Anthracite

OPERATION

- Place the workpiece between the jaws of the vice
- Move jaws and clamp workpiece by actuating the spindle

MASTER DATA

GTIN [EAN]	4027474925185
Country of origin	DE
Case material	Tool steel
Series	525
Net weight [kg]	6,89 kg
Package contents	1 piece
Packaging Act	PP 05
Global sales capability given	Yes (REACH, RoHS, POP, PROP65, TSCA)

SPARE PARTS

- 525-101_Interchangeable clamping jaws
- 525-102_Turntable for vice
- 545-100_Vice jaws with magnetic strip, aluminium, smooth
- 545F100_Vice jaws with magnetic strip, felt, red
- 545G100_Vice jaws with magnetic strip, aluminum with rubber, grey
- 550-100_Vice jaws, aluminium with prisms