




43 4004_12,5





ELECTRONIC DIGITAL INDICATOR INSTRUCTIONS

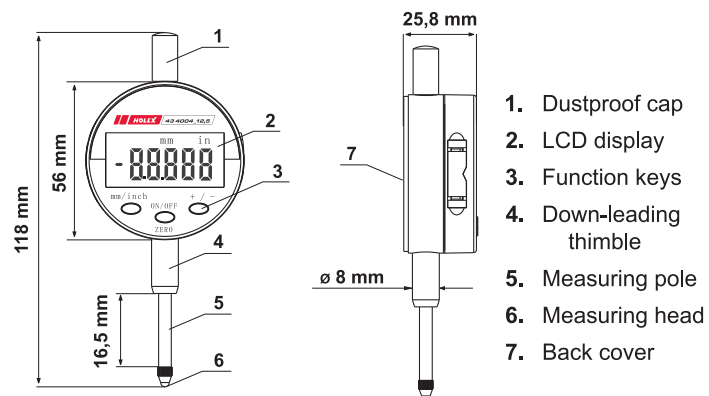

NOTE: There are three function keys including:
[ON/OFF], **[mm/inch]**, **[+/-]**

Parameters of the Electronic Digital Indicator

Minimal Resolution	0,01 mm / 0,0005 inch
Measuring Range	12,5 mm / 0,5 inch
Accuracy	0,02 mm / 0,001 mm
Stem Diameter	$\varnothing 8^{+0}_{-0,015}$ mm
Measuring Force	$\leq 1,5$ N
Measuring Speed	$\geq 1,5$ m/s
Battery	3V CR 2032
Current Consumption	≤ 90 μ A
Operating Temperature	0 C° ~ 40 C°
Storing Temperature	-10 C° ~ 60 C°
Weight	≈ 100 g

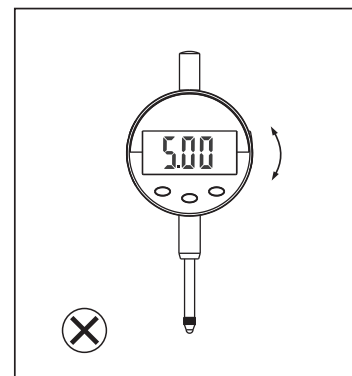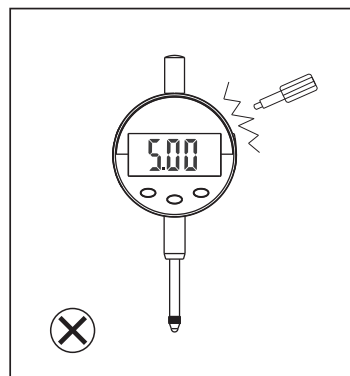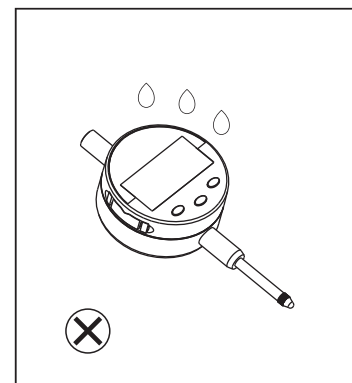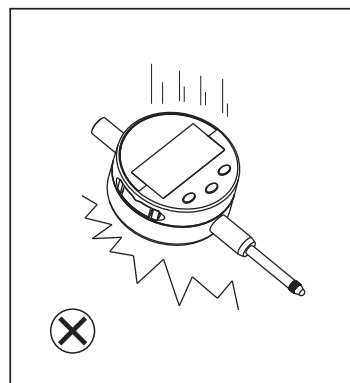

$f_t = 0,025$ mm

$f_w = 0,01$ mm

$f_e = 0,025$ mm

$f_{ges} = 0,025$ mm