


## Notlære med talmæssig tolerance, Type: F

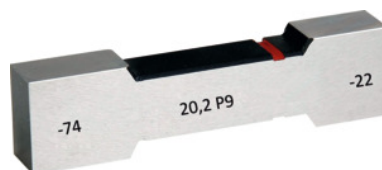

### Bestillingsdata

Bestillingsnummeret	484408 F
GTIN	2050001956620
Artikelklasse	48B

### Beskrivelse

#### VIGTIGT: Denne artikel kan konfigureres

Nom. mål: 21.001 - 25.999 mm

Kvalitet: 10; 11; 12; 13; 7; 8; 9

Tolerancefelt: A; B; C; CD; D; E; EF; F; FG; G; H; J; JS; K; M; N; P; R; S; T; U; V; X; Z; ZA; ZB; ZC

#### Udførelse:

Notlærer med go- og nogo-side. Go-side med **slidovermål** iht. DIN 7164. Læreenhed i hærdet stål.

Til mellem mål eller talmæssig tolerance.

#### Anvendelse:

Til kontrol af fladpasninger f.eks. fra noter.

#### Norm:

Toleranzen und Abmaße nach **DIN 1938-1, DIN 2245-1 und DIN 7163.**

#### Bemærk:

Eksempel: 15,8 m6 eller 41,04 + 0,01 / – 0,02.

Kalibrering: L6

Nom. mål: 21,001 - 25,999 mm

### Teknisk beskrivelse

Nom. mål	21,001 - 25,999 mm
Kvalitet	7
Kvalitet	8
Kvalitet	9

Kvalitet	10
Kvalitet	11
Kvalitet	12
Kvalitet	13
Tolerancefelt	G
Tolerancefelt	A
Tolerancefelt	B
Tolerancefelt	C
Tolerancefelt	CD
Tolerancefelt	D
Tolerancefelt	E
Tolerancefelt	EF
Tolerancefelt	F
Tolerancefelt	FG
Tolerancefelt	J
Tolerancefelt	H
Tolerancefelt	JS
Tolerancefelt	K
Tolerancefelt	N
Tolerancefelt	M
Tolerancefelt	P
Tolerancefelt	R
Tolerancefelt	S
Tolerancefelt	U
Tolerancefelt	T
Tolerancefelt	V
Tolerancefelt	X
Tolerancefelt	Z
Tolerancefelt	T

Tolerancefelt	ZA
Tolerancefelt	ZB
Tolerancefelt	ZC
Tolerancefelt	A
Tolerancefelt	G
Tolerancefelt	H
Tolerancefelt	J
Tolerancefelt	K
Tolerancefelt	M
Tolerancefelt	N
Tolerancefelt	P
Tolerancefelt	R
Tolerancefelt	S
Tolerancefelt	B
Tolerancefelt	T
Tolerancefelt	U
Tolerancefelt	V
Tolerancefelt	X
Tolerancefelt	Y
Tolerancefelt	Z
Tolerancefelt	ZA
Tolerancefelt	ZB
Tolerancefelt	ZC
Tolerancefelt	C
Tolerancefelt	D
Tolerancefelt	E
Tolerancefelt	F
Tolerancefelt	CD
Tolerancefelt	EF

Tolerancefelt	FG
Tolerancefelt	JS
Kalibrering	L6
Produkttype	Toleranceaksellære

**Services**

Kalibrering Tolerancedorn maks. Ø 60 mm	018400 60
DAkKS-kalibrering Tolerancedorn maks. Ø 60 mm	019620 60
Mærkning laserindgraveret Type	018940
Kalibrering Tolerancedorn maks. Ø 60 mm	028300 60
DAkKS-kalibrering Tolerancedorn maks. Ø 60 mm	028340 60