




## Modular vice long, Jaw width A: 125mm

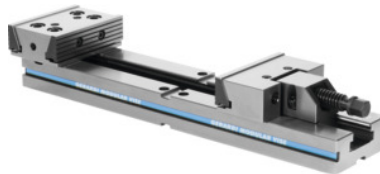

### Order data

|              |               |
|--------------|---------------|
| Order number | 362105 125    |
| GTIN         | 2050001774262 |
| Item class   | 35G           |

### Description

#### Version:

- Simple mechanical actuation (up to 3.5 t).
- Easy adjustment of jaw opening.
- Machine vice with pull-down jaws.
- Case-hardened HRC 60.
- Parallelism 0.02 mm.

#### Supplied with:

Supplied with pull-down jaws, 1 workpiece backstop, 2 T-nuts No. 362160 size 16/16, 1 clamping wrench, 1 cross-bar wrench.

#### Note:

See No. 362160 for other T-nuts.

### Technical description

|                                      |             |
|--------------------------------------|-------------|
| Clamping range b                     | 320 mm      |
| Base body height G                   | 40 mm       |
| Jaw height C                         | 40 mm       |
| Colour code for suitable accessories | Gerardi 125 |
| Transverse tenon slot n              | 16 mm       |
| Longitudinal tenon slot l            | 16 mm       |
| Jaw width A                          | 125 mm      |

|                                 |              |
|---------------------------------|--------------|
| Overall length L                | 520 mm       |
| Weight                          | 18.3 kg      |
| maximum clamping force at 60 Nm | 25 kN        |
| Series                          | Gerardi 125  |
| Type of product                 | Machine vice |

## Accessories

|  |              |
|--|--------------|
| Pair of T-nuts T-slot dimension B / keyway 12/16 mm            | 362160 12/16 |
| Movable jaw (piece) for jaw width 125 mm                       | 362143 125   |
| Pair of T-nuts T-slot dimension B / keyway 18/16 mm            | 362160 18/16 |
| Longitudinally serrated front jaw (piece) for jaw width 125 mm | 362146 125   |
| Complete clamping element (piece) for jaw width 125 mm         | 362144 125   |
| Prismatic jaw (piece) for jaw width 125 mm                     | 362125 125   |
| Modular element movable (piece) for jaw width 125 mm           | 362145 125   |
| Pair of T-nuts T-slot dimension B / keyway 16/16 mm            | 362160 16/16 |
| Smooth front jaw, hard (piece) for jaw width 125 mm            | 362147 125   |
| Pair of clamps for jaw width 125 mm                            | 362120 125   |
| Pair of T-nuts T-slot dimension B / keyway 20/16 mm            | 362160 20/16 |
| Modular element fixed (piece) for jaw width 125 mm             | 362150 125   |
| Smooth front jaw, soft (piece) for jaw width 125 mm            | 362148 125   |
| Pair of T-nuts T-slot dimension B / keyway 14/16 mm            | 362160 14/16 |